



Viking™ 3 accessories for terminal blocks (continued)

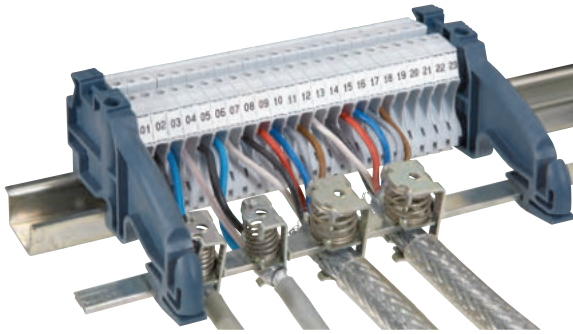

Shielding terminal block with end stops 0 375 12, bar 0 375 34 and clamps 0 375 30/31




0 375 76 + 0 371 64

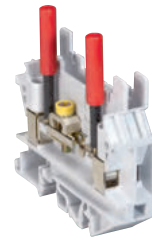

0 375 77 + 0 371 92 open




0 375 66 + 0 371 63 + 0 371 03


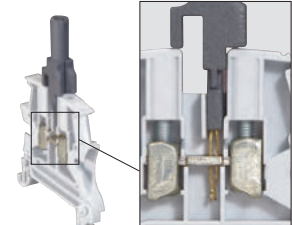


0 375 27 + 0 371 61

Pack	Cat.Nos	Shielding accessories
		Ensure safe, simple connection of cable shielding
		Shielding clamps
		For screw and spring terminal blocks
		- mounted by pivoting on collector bar
		- 10 x 3 mm Cat.No 0 375 34
		- mounted on plate with M4 screws (supplied)
		- mounted on rail with Cat.No 0 364 69
10	0 375 30	For cable Ø3 to 8 mm
10	0 375 31	For cable Ø4 to 13.5 mm
4	0 375 32	For cable Ø10 to 20 mm
		Shielding bar
		For screw and spring terminal blocks
		Steel
		Length 1 m
		For use with end stops Cat.No 0 375 12
10	0 375 34	10 x 3 mm
		Screening continuity bracket
50	0 375 35	For screw terminal blocks 1 entry/1 outlet
		5, 6, 8 and 10 mm pitch
		Connected with 2.8 x 0.8 mm clips or welded on
		Capacity: 1 mm ²

 

Pack	Cat.Nos	Protective screens
		1 pole
		For screw terminal blocks 1 entry/1 outlet
10	0 375 65	5 and 6 mm pitch
10	0 375 66	8 and 10 mm pitch
10	0 375 67	12 and 15 mm pitch
		Cut to length
		Length 1 m
		Mounted on separation and insulation divider
		For screw terminal blocks 1 entry/1 outlet
		Can be equipped with CAB 3 marking system for terminal blocks (p. 342)
10	0 375 68	5, 6, 8 and 10 mm pitch
		(divider Cat.No 0 375 60)
10	0 375 69	12 and 15 mm pitch
		(divider Cat.No 0 375 61)
		Measurement accessories
		For screw and spring terminal blocks
10	0 375 271	Measurement socket for Ø4 mm plug for blocks with 5, 6 and 8 mm pitch
50	0 375 75	Measurement socket for Ø2 mm plug for blocks with 10 mm pitch Cat.Nos 0 371 03/63
20	0 375 76	Measurement socket for Ø4 mm plug for blocks with 12 and 15 mm pitch Cat.Nos 0 371 04/05/64/65
10	0 375 77	Measurement socket for Ø4 mm plug for disconnect block for measurement Cat.No 0 371 92

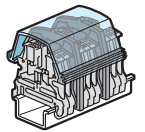 

1: Except for disconnect blocks with handle lever, screw terminal block with LED and spring function blocks. 2 and 3-level terminal blocks: upper level only. Side by side installation of 2 measurement sockets is possible only with 8 mm pitch blocks