
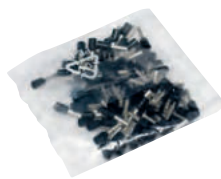
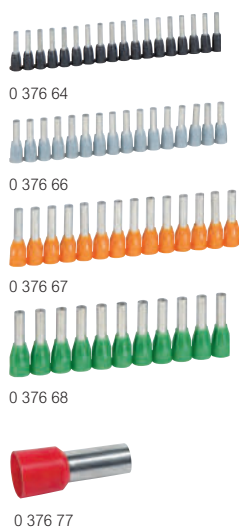


# Starfix™ ferrules and crimping tools

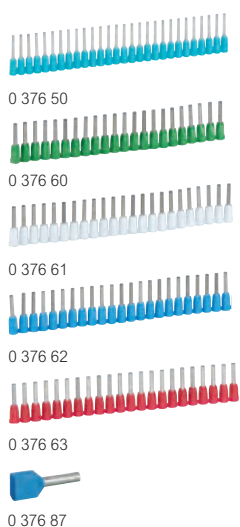

Correspondence table and dimensions p. 473

Pack	Cat.Nos	Ferrules with insulating flange			
		Provide an equipotential link for all the strands of a copper flexible conductor Active part in tinned electrolytic copper Conform to NF C 63-023			
		<b>Singles - supplied in strips</b>			
		Cross-section (mm <sup>2</sup> )	Colour	Number of strips or sachets	Number of ferrules per strip or sachet
500	0 376 50	0.25	turquoise	10	50
500	0 376 60	0.34	green	10	50
480	0 376 61	0.5	white	12	40
480	0 376 62	0.75	blue	12	40
1000	0 376 63	1	red	25	40
1000	0 376 64	1.5	black	25	40
1000	0 376 66	2.5	grey	25	40
250	0 376 67	4	orange	10	25
250	0 376 68	6	green	10	25
		<b>Singles - individual ferrules (sachet packing)</b>			
500	0 377 50	0.25	turquoise	5	100
500	0 377 60	0.34	green	5	100
1000	0 377 61	0.5	white	10	100
1000	0 377 62	0.75	blue	10	100
1000	0 377 63	1	red	10	100
1000	0 377 64	1.5	black	10	100
1000	0 377 66	2.5	grey	10	100
250	0 377 67	4	orange	5	50
250	0 377 68	6	green	5	50
		<b>Singles - individual ferrules (box packing)</b>			
100	0 376 69	10	brown		
100	0 376 72 <sup>1</sup>	16	white		
100	0 376 70	16	white		
50	0 376 71	25	black		
50	0 376 77	35	red		
30	0 376 78	50	blue		
		<b>Doubles - individual ferrules</b>			
500	0 376 87	2 x 0.75	blue		
500	0 376 88	2 x 1	red		
500	0 376 89	2 x 1.5	black		
500	0 376 90	2 x 2.5	grey		
		<b>Singles - supplied as refills</b>			
		Large capacity for less frequent applicator reloading Refills for direct mounting on crimping tool Cat.No 0 376 09			
		Cross-section (mm <sup>2</sup> )	Colour	Number of ferrules per refills	
3000	0 376 41	0.5	white	300	
3000	0 376 42	0.75	blue	300	
3000	0 376 43	1	red	300	
3000	0 376 44	1.5	black	300	
2500	0 376 45	1.5	grey	250	

1: Short ferrule

Pack	Cat.Nos	Crimping tools for ferrules in strips	
		Cut and crimp of ferrules from 0.25 to 6 mm <sup>2</sup> in one operation	
1	0 376 08	<b>Starfix crimping tool for 0.25 and 0.34 mm<sup>2</sup> cross-sections</b> Supplied fitted with empty applicator	
1	0 376 09	<b>Starfix crimping tool for 0.5 to 2.5 mm<sup>2</sup> cross-sections</b> Supplied fitted with empty applicator	
1	0 376 39	Assorted kit, comprising: - 1 Starfix crimping tool, Cat. No. 0 376 09 fitted with empty applicator - 120 x 0.5 mm <sup>2</sup> ferrules - 120 x 0.75 mm <sup>2</sup> ferrules - 240 x 1 mm <sup>2</sup> ferrules - 320 x 1.5 mm <sup>2</sup> ferrules - 200 x 2.5 mm <sup>2</sup> ferrules	
1	0 376 10	<b>Starfix crimping tool for 4 and 6 mm<sup>2</sup> cross-sections</b> Supplied fitted with empty applicator	
1	0 376 97	<b>Starfix S multi-purpose crimping tool for 0.5 to 2.5 mm<sup>2</sup> cross-sections</b> Tool cuts, strips, twists and crimps wire Supplied with 5 empty applicators	
		<b>Crimping tool for individual single and double ferrules</b>	
		For right or left-handed	
		<b>Starfix crimping tool for 0.14 to 10 mm<sup>2</sup> cross-sections</b>	
1	0 376 06	For crimping of 0.14 to 10 mm <sup>2</sup> cross section ferrules Crimping tool with disengageable control system, square crimping profile	
1	0 376 92	<b>Starfix crimping tool for 10 to 50 mm<sup>2</sup> cross-sections</b> Assorted kit comprising: - 1 crimping tool with disengageable control system for individual ferrules 10 to 50 mm <sup>2</sup> ; 4-point crimping - 30 individual ferrules 10 mm <sup>2</sup> - 20 individual ferrules 16 mm <sup>2</sup> - 15 individual ferrules 25 mm <sup>2</sup> - 10 individual ferrules 35 mm <sup>2</sup> - 10 individual ferrules 50 mm <sup>2</sup>	