


CAB 3™ marking system  
for wiring or Viking 3 terminal blocks

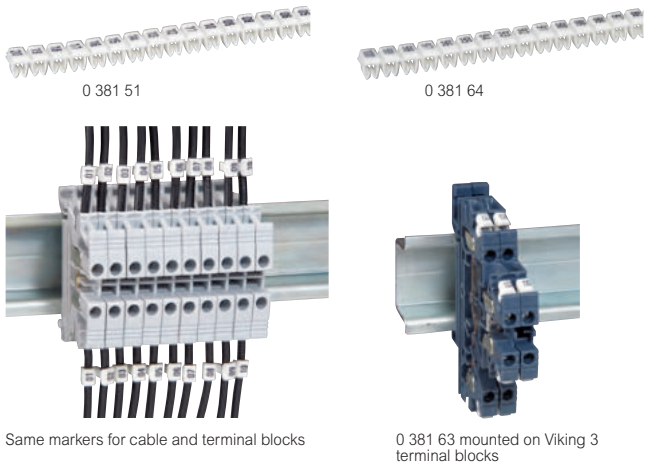

Technical characteristics p. 476

For marking wiring or Viking 3 terminal blocks

Pack	Cat.Nos	Markers for wiring 0.5 to 1.5 mm² cross-section and terminal blocks
		Strips of 20 markers (price per marker) Numbers: black on white background (available in black on yellow background on request)
240	0 381 50	01 to 20
240	0 381 51	21 to 40
240	0 381 52	41 to 60
240	0 381 53	61 to 80
240	0 381 54	81 to 100
240	0 381 55	Blank

0 381 51

Pack	Cat.Nos	Markers for wiring 1.5 to 2.5 mm² cross-section
		Strips of 20 markers (price per marker) Numbers: black on white background (available in black on yellow background on request)
240	0 381 60	01 to 20
240	0 381 61	21 to 40
240	0 381 62	41 to 60
240	0 381 63	61 to 80
240	0 381 64	81 to 100
240	0 381 65	Blank

0 381 64

Marking label sheets  
for Viking 3 terminal blocks



For marking Viking 3 terminal blocks

Pack	Cat.Nos	Blank markers
		Displayed by sheet of 100 pre-cut markers Manual marking (price per marker)
1000	0 395 00	For blocks 5 mm pitch
1000	0 395 01	For blocks 6 mm pitch
1000	0 395 02	For blocks 8 mm pitch

Pack	Cat.Nos	Numbers
		Correct reading direction with the marker in horizontal position. Price per marker.
		<b>Pitch of 5 mm</b>
1000	0 395 05	From 1 to 10 (10 times)
1000	0 395 06	From 11 to 20 (10 times)
1000	0 395 07	From 21 to 30 (10 times)
1000	0 395 08	From 31 to 40 (10 times)
1000	0 395 09	From 1 to 50 (2 times)
1000	0 395 10	From 1 to 100
1000	0 395 11	From 101 to 200
		<b>Pitch of 6 mm</b>
1000	0 395 15	From 1 to 10 (10 times)
1000	0 395 16	From 11 to 20 (10 times)
1000	0 395 17	From 21 to 30 (10 times)
1000	0 395 18	From 31 to 40 (10 times)
1000	0 395 19	From 1 to 50 (2 times)
1000	0 395 20	From 1 to 100
1000	0 395 21	From 101 to 200

Pack	Cat.Nos	Black felt tip pen
10	0 395 98	Indelible for marking