

CAB 3™ marking system


markers for wiring and Viking 3 terminal blocks



Perfect alignment of label holders



0 382 12

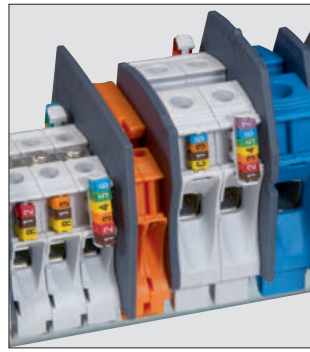

Terminal block with CAB 3 markers and label-holders



More practical packaging

For marking wiring or Viking 3 terminal blocks

Pack	Cat.Nos		<p>Markers for wiring 0.15 to 0.5 mm² and 0.5 to 1.5 mm² cross-section and terminal blocks</p> <p>On Viking 3 terminal blocks - 4 markers 0.15 to 0.5 mm² max - 3 markers 0.5 to 1.5 mm² max.</p> <p>Pack: - Up to 0.5 mm²: strips of 25 markers From 0.5 mm² to 1.5 mm²: strips of 30 markers</p> <p>Price per marker</p> <p>Digits: international colour code</p>
1000 1200	0.15 to 0.5 ²	0.5 to 1.5 ²	
1000 1200	0 381 00	0 382 10	
1000 1200	0 381 01	0 382 11	
1000 1200	0 381 02	0 382 12	
1000 1200	0 381 03	0 382 13	
1000 1200	0 381 04	0 382 14	
1000 1200	0 381 05	0 382 15	
1000 1200	0 381 06	0 382 16	
1000 1200	0 381 07	0 382 17	
1000 1200	0 381 08	0 382 18	
1000 1200	0 381 09	0 382 19	
			 0 381 06
			 0 383 17
			 0 381 28
			 0 382 72
			 0 381 43
300	0 381 10	0 383 00	Letters: black on yellow background
300	0 381 11	0 383 01	A
300	0 381 12	0 383 02	B
300	0 381 13	0 383 03	C
300	0 381 14	0 383 04	D
300	0 381 15	0 383 05	E
300	0 381 16	0 383 06	F
300	0 381 17	0 383 07	G
300	0 381 18	0 383 08	H
300	0 381 19	0 383 09	I
300	0 381 20	0 383 10	J
300	0 381 21	0 383 11	K
300	0 381 22	0 383 12	L
300	0 381 23	0 383 13	M
300	0 381 24	0 383 14	N
300	0 381 25	0 383 15	O
300	0 381 26	0 383 16	P
300	0 381 27	0 383 17	Q
300	0 381 28	0 383 18	R
300	0 381 29	0 383 19	S
300	0 381 30	0 383 20	T
300	0 381 31	0 383 21	U
300	0 381 32	0 383 22	V
300	0 381 33	0 383 23	W
300	0 381 34	0 383 24	X
300	0 381 35	0 383 25	Y
300			Z
300	0 381 40	0 382 70	Conventional symbols: black on yellow background
300	0 381 41	0 382 71	/
300	0 381 42	0 382 72	•
300	0 381 43	0 382 73	+
300	0 381 44	0 382 74	-
300	0 381 45	0 382 75	~
300	0 381 46	0 382 76	≡
300			⊕

Pack	Cat.Nos		<p>Markers for wiring 1.5 to 2.5 mm² and 4 to 6 mm² cross-section</p> <p>Pack: From 1.5 mm² to 2.5 mm²: strips of 30 markers - Upper 2.5 mm²: strips of 20 markers</p> <p>Price per marker</p> <p>Digits: international colour code</p>
	1.5 to 2.5 ²	4 to 6 ²	
1200 800	0 382 20	0 382 30	
1200 800	0 382 21	0 382 31	
1200 800	0 382 22	0 382 32	
1200 800	0 382 23	0 382 33	
1200 800	0 382 24	0 382 34	
1200 800	0 382 25	0 382 35	
1200 800	0 382 26	0 382 36	
1200 800	0 382 27	0 382 37	
1200 800	0 382 28	0 382 38	
1200 800	0 382 29	0 382 39	
300	0 383 30	0 383 60	
300	0 383 31	0 383 61	
300	0 383 32	0 383 62	
300	0 383 33	0 383 63	
300	0 383 34	0 383 64	
300	0 383 35	0 383 65	
300	0 383 36	0 383 66	
300	0 383 37	0 383 67	
300	0 383 38	0 383 68	
300	0 383 39	0 383 69	
300	0 383 40	0 383 70	
300	0 383 41	0 383 71	
300	0 383 42	0 383 72	
300	0 383 43	0 383 73	
300	0 383 44	0 383 74	
300	0 383 45	0 383 75	
300	0 383 46	0 383 76	
300	0 383 47	0 383 77	
300	0 383 48	0 383 78	
300	0 383 49	0 383 79	
300	0 383 50	0 383 80	
300	0 383 51	0 383 81	
300	0 383 52	0 383 82	
300	0 383 53	0 383 83	
300	0 383 54	0 383 84	
300	0 383 55	0 383 85	
300	0 382 80	0 382 90	
300	0 382 81	0 382 91	
300	0 382 82	0 382 92	
300	0 382 83	0 382 93	
300	0 382 84	0 382 94	
300	0 382 85	0 382 95	
300	0 382 86	0 382 96	



0 382 32



0 382 26



0 383 46



0 383 79



0 382 96