

Arteor™

dimmers



5 727 13



5 735 01



5 722 39A

Support frame and plate selection charts p. 594-603
Load selection charts p. 564


Mechanisms supplied with rocker plates, to be equipped with support frames (p. 585) and plates (p. 594-603)

Pack	Cat.Nos	Leading edge dimmers
1	5 722 13	Without neutral, 2-wire 2 modules
1	5 727 13	Rotary dimmer - 400 W
1	5 700 53	○ White
1	5 710 53	● Magnesium
		● Champagne
		● Soft Alu
		Rotary dimmer - 1000 W
		To be installed alone in a 3 module box (or 1-gang BS) with a 3-module support frame and a 2-module plate
		For lamps:
		- 60-1000 W (230 V) - 60-500 W (127 V) for incandescent and halogen lamps
		- 60-600 VA (230 V) - 60-300 VA (127 V) for halogen lamps with electronic transformer with leading edge behaviour
		- 60-1000 VA (230 V) - 60-500 VA (127 V) for halogen lamps with ferromagnetic transformers
1	5 735 01	○ White
1	5 737 01	● Magnesium
		Dimmers for all dimmable loads
		Can be associated with one or several push-buttons without neon, for ON/OFF or dimming control
		Memory level function: lights come on again at the same lighting level as before they were last switched OFF
		Depth 35 mm
		Standby consumption < 5 mW
		2 modules
		Push-button dimmer without neutral, 2 wires
		For ON/OFF and dimming control of all types of lamps:
		- Dimmable LEDs and CFL lamps: 3 to 125 W LED (10 lamps max.)
		- Halogen and incandescent 230 V~ : 3 to 125 W
		- LEDs CFLs, halogen lamps, fluorescent tubes with ferromagnetic or electronic transformer: 3 to 125 VA
1	5 722 39A	○ White
1	5 727 39A	● Magnesium
1	5 729 37A	● Champagne
1	5 729 36A	● Soft Alu
		Push-button dimmer with neutral, 3 wires
		For ON/OFF and dimming control of all types of lamps:
		- Dimmable LEDs and CFL lamps: 0 to 150 W LED (15 lamps max.)
		- Halogen and incandescent 230 V~ : 0 to 150 W
		- LEDs, CFLs, halogen lamps, fluorescent tubes with ferromagnetic or electronic transformer: 0 to 150 VA
1	5 741 89A	○ White
1	5 741 90A	● Magnesium
1	5 741 91A	● Champagne
1	5 741 88A	● Soft Alu
		Dimmers 1-10 V
		Push-button dimmer for ballasts 1-10 V
		2 modules
1	5 722 38	○ White
1	5 727 38	● Magnesium
1	5 729 39	● Champagne
1	5 729 38	● Soft Alu

NEW DIMMERS & MOTION SENSORS

LED there be light

Fully LED compatible, this new generation of Arteor dimmers and motion sensors is not only designed to work with any type of LED. They are suitable for all modern loads.

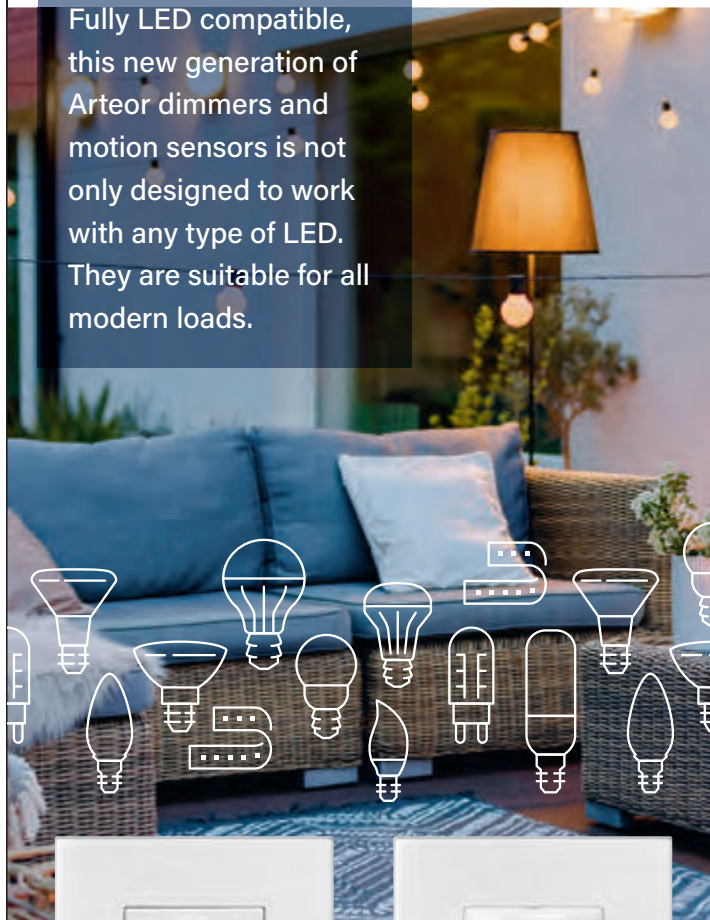

Dimmers for all dimmable loads

- Available with or without neutral
- Suitable for all kinds of dimmable LEDs and modern loads



Motion sensors

- Available with or without neutral
- Compatible with all types of LEDs
- Reduced depth 25 mm for easy installation