

Arteor™

visual indication



5 722 21



 
5 727 26




5 724 52



5 722 67



Lamp used as a torch

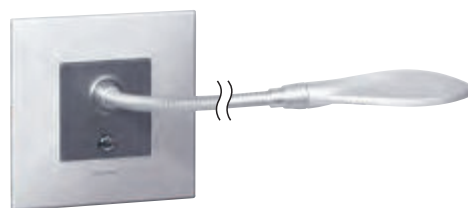

5 727 57 + plate 5 713 02

Support frame and plate selection charts **p. 594-603**

Mechanisms supplied with square rocker plates, to be equipped with support frames (p. 585) and plates (p. 594 to 603)

Pack	Cat.Nos	Skirting lights
		For installation close to obstacles 2 modules
		Standard
		With LED 230 V~ - 0.2 or 1 W
1	5 722 21	○ White
1	5 740 82	● Magnesium
1	5 740 83	● Champagne
1	5 740 80	● Soft Alu
		With motion detector 100-240 V~
		With IR detection cell and LED
		When a person passes, the mechanism detects the presence and lights the obstacle
		The function is equipped with an audible signal that can be disengaged
1	5 722 26	○ White
1	5 727 26	● Magnesium
1	5 729 45	● Champagne
1	5 729 44	● Soft Alu
		Self-contained plug-in lights
		230 V~ power supply
		In the event of a mains failure, the lamp lights up automatically
		When removed from its socket, the lamp lights up automatically and can be used as a torch (with O/I button)
		Lamp can be removed simply by pushing
		Standby power: 24 hrs in use
1	5 722 67	○ Transparent

Pack	Cat.Nos	Reading lights
		Fitted with maintenance-free LEDs
		LED colours: 3000 K (neutral white)
		230 V~ power supply - energy class A
		Screw terminals
		For installation in the bedhead
		Offers directional lighting
		Equipped with a flexible cable so the head can swivel
		Built-in dimmer
		Consumption 3.3 W
		Luminous flux 110 lumen (equivalent to 15 W incandescent)
		Service life 40000 hours
		For installation in box depth 40 mm min.
		2 modules
		Square version
1	5 722 57	○ White
1	5 727 57	● Magnesium

Pack	Cat.Nos	Illuminated lighting unit
		230 V~ - 1 W
		Supplied with 4 coloured labels
10	5 724 52	○ White

Pack	Cat.Nos	Overdoor lighting units
		Supplied with diffusers and LED
		2 modules
10	5 724 53	○ White with red diffuser
10	5 722 23	○ White with white diffuser

Pack	Cat.Nos	Lamps
		For locator switch
10	5 724 56	LED 230 V - blue
		For indicator switch
10	5 724 55	LED 230 V - red
10	5 724 57	LED 24 V - red
10	5 724 54	LED 12 V - red