



5 721 56A + plate 5 751 11A




5 726 29A + plate 5 754 58



5 726 58A



5 722 86 + plate 5 754 37

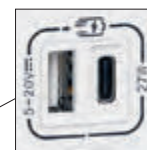

Mechanisms supplied with rocker plates, to be equipped with special plates
Support frame not needed

Pack	Cat.Nos	British standard socket outlets 13 A - 250 V~ with USB charger
		Conform to BS 1363-2
		1-gang single pole switched USB Type-A 3 A - 5 V_{DC} - 15 W Consumption in passive mode < 0.07 W
1	5 721 56A	<ul style="list-style-type: none"> ○ White ● Magnesium ● Champagne ● Soft Alu
1	5 726 56A	
1	5 710 80A	
1	5 700 80A	
		1-gang single pole switched USB Type-C 18 W Fast charge feature: USB Type-C Power Delivery Consumption in passive mode < 0.07 W
1	5 721 29A	<ul style="list-style-type: none"> ○ White ● Magnesium ● Champagne ● Soft Alu
1	5 726 29A	
1	5 722 29A	
1	5 722 49A	
		1-gang single pole unswitched USB Type-A 3 A - 5 V_{DC} - 15 W Consumption in passive mode < 0.07 W
1	5 721 58A	<ul style="list-style-type: none"> ○ White ● Magnesium ● Champagne ● Soft Alu
1	5 726 58A	
1	5 710 82A	
1	5 700 82A	
		1-gang single pole unswitched USB Type-C 18 W Fast charge feature: USB Type-C Power Delivery Consumption in passive mode < 0.07 W
1	5 721 27A	<ul style="list-style-type: none"> ○ White ● Magnesium ● Champagne ● Soft Alu
1	5 726 27A	
1	5 722 28A	
1	5 722 58A	
		2-gang single pole switched USB Type-A + Type-C 3 A - 5 V_{DC} - 15 W Consumption in passive mode < 0.07 W
1	5 721 42	<ul style="list-style-type: none"> ○ White ● Magnesium ● Champagne ● Soft Alu
1	5 726 42	
1	5 710 81	
1	5 700 81	
		2-gang single pole switched USB Type-A + Type-C 27 W Fast charge feature: USB Type-C Power Delivery Consumption in passive mode < 0.07 W
1	5 722 86	<ul style="list-style-type: none"> ○ White ● Magnesium ● Champagne ● Soft Alu
1	5 728 07	
1	5 700 85	
1	5 710 68	

Pack	Cat.Nos	Plates for British standard socket outlets - 13 A - 250 V~ with USB charger
		For 1-gang single pole switched USB Type-A 3 A - 5 V_{DC} - 15 W
5	5 751 11A	<ul style="list-style-type: none"> ○ White ● Soft Alu ● Graphite ● Magnesium ● Champagne ● Dark Bronze ● Brushed Metal - Stainless Steel
5	5 751 34A	
5	5 751 33A	
5	5 751 35A	
5	5 751 36A	
5	5 751 37A	
1	5 751 12A	
		For 1-gang single pole switched USB Type-C 18 W
5	5 754 52	<ul style="list-style-type: none"> ○ White ● Soft Alu ● Graphite ● Magnesium ● Champagne ● Dark Bronze ● Brushed Metal - Stainless Steel
5	5 754 53	
5	5 754 54	
5	5 754 55	
5	5 754 56	
5	5 754 57	
1	5 754 58	
		For 1-gang single pole unswitched USB Type-A 3 A - 5 V_{DC} - 15 W
5	5 751 13A	<ul style="list-style-type: none"> ○ White ● Soft Alu ● Graphite ● Magnesium ● Champagne ● Dark Bronze ● Brushed Metal - Stainless Steel
5	5 751 89A	
5	5 751 88A	
5	5 751 93A	
5	5 751 94A	
5	5 751 95A	
1	5 751 14A	
		For 1-gang single pole unswitched USB Type-C 18 W
5	5 754 59	<ul style="list-style-type: none"> ○ White ● Soft Alu ● Graphite ● Magnesium ● Champagne ● Dark Bronze ● Brushed Metal - Stainless Steel
5	5 754 61	
5	5 754 62	
5	5 754 63	
5	5 754 64	
5	5 754 65	
1	5 754 66	
		For 2-gang single pole switched USB Type-A + Type-C 3 A - 5 V_{DC} - 15 W
5	5 751 17	<ul style="list-style-type: none"> ○ White ● Soft Alu ● Graphite ● Magnesium ● Champagne ● Dark Bronze ● Brushed Metal - Stainless Steel
5	5 751 52	
5	5 751 51	
5	5 751 53	
5	5 751 54	
5	5 751 55	
1	5 751 18	
		For 2-gang single pole switched USB Type-A + Type-C 27 W
5	5 754 37	<ul style="list-style-type: none"> ○ White ● Soft Alu ● Graphite ● Magnesium ● Champagne ● Dark Bronze ● Brushed Metal - Stainless Steel
5	5 754 39	
5	5 754 40	
5	5 754 41	
5	5 754 42	
5	5 754 43	
1	5 754 38	