

## Arteor™

### telephone sockets




Support frame and plate selection charts **p. 594-603**

Mechanisms supplied with rocker plates, to be equipped with support frames (p. 585) and plates (p. 594-603)

Pack	Cat.Nos	<b>RJ 11 and RJ 12 sockets</b>
		Equipped with modular Jack connector with 1/4 turn terminal for fast connection (possible looping)
		<b>RJ 11 - 1 module</b> 4 contacts
10	5 723 00	○ White
10	5 728 00	● Magnesium
10	5 700 56	● Champagne
10	5 710 56	● Soft Alu
		<b>RJ 11 - 2 modules</b> 4 contacts
10	5 723 13	○ White
10	5 728 13	● Magnesium
10	5 726 83	● Champagne
10	5 726 82	● Soft Alu
		<b>RJ 12 - 2 modules</b> 6 contacts
10	5 723 12	○ White
10	5 728 12	● Magnesium
10	5 726 85	● Champagne
10	5 726 84	● Soft Alu
		<b>Telephone sockets</b>
		With IDC connection Conform to British Telecom
		<b>Single master - 2 modules</b>
10	5 723 10	○ White
10	5 728 10	● Magnesium
10	5 726 87	● Champagne
10	5 726 86	● Soft Alu
		<b>Single secondary - 1 module</b>
5	5 723 01	○ White
5	5 728 01	● Magnesium
5	5 726 89	● Champagne
5	5 726 88	● Soft Alu

## Arteor™

### television sockets

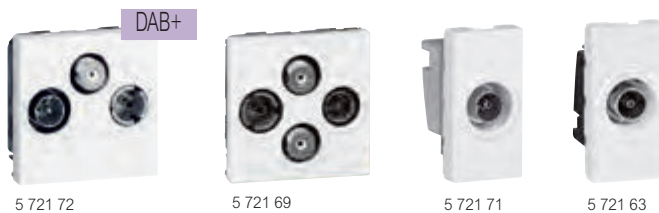

Support frame and plate selection charts **p. 594-603**

Mechanisms supplied with rocker plates, to be equipped with support frames (p. 585) and plates (p. 594-603)

For Dvbt, Cablecast and satellite installation  
UHD TV quality compatible  
Classe A shielded star socket LTE ready (4G protected)  
Recommended coaxial cable: 17 VATCA  
Star cabling (1 socket = 1 cable to antenna, splitter or multiswitch)  
Visual check of the connection  
Meets EN 50083-4 and EN 50083-2 European directive

Pack	Cat.Nos	<b>Multi TV star sockets</b>
		<b>TV-R-SAT sockets</b> DAB+ Low attenuation: 1.5 dB 2 modules
10	5 721 72	○ White
10	5 726 72	● Magnesium
10	5 726 91	● Champagne
10	5 726 90	● Soft Alu
		<b>TV-R-SAT-SAT sockets</b> In1: TV-R-SAT1 / In2: SAT2 Low attenuation: 1.5 dB 2 modules
10	5 721 69	○ White
10	5 726 69	● Magnesium
10	5 726 93	● Champagne
10	5 726 92	● Soft Alu
		<b>TV-SAT sockets</b> 1 module
10	5 721 67	○ White
10	5 726 67	● Magnesium
10	5 726 95	● Champagne
10	5 726 94	● Soft Alu
		<b>Single TV star sockets - 1 module</b> Low attenuation 1dB 1 module
		<b>TV 9.5 mm male sockets</b>
10	5 721 71	○ White
10	5 726 71	● Magnesium
10	5 700 51	● Champagne
10	5 710 51	● Soft Alu
		<b>TV "F" type sockets</b>
10	5 721 63	○ White
10	5 726 63	● Magnesium
10	5 700 50	● Champagne
10	5 710 50	● Soft Alu