

# Arteor™ with Netatmo - British standard

connected socket outlets

# Arteor™

plates for connected socket outlets

## Step 2: Connected products



Home + Control




5 742 56



5 742 68



5 751 60

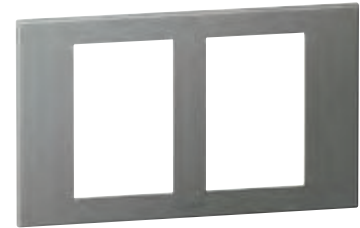

5 712 13

Plate selection charts p. 594 to 597

Used to create your connected installation, require prior installation of a gateway pack for connected installation  
Conform to BS 1363-2 and IEC 60669-2-5  
Zigbee Certified Product

Plate selection charts p. 594 to 597

### Connected British standard socket outlets, 13 A - 250 V, switched, single pole

Pack	Cat.Nos	Description
		Compact mechanism (22 mm deep) Shuttered for child safety Protected against overloads Socket outlets can be controlled by one or several connected wireless light switches Remote control via the Home + Control App. Compatible with any electrical appliance or large household appliance Connected socket outlets allow to: - remotely control electrical appliances - measure instantaneous power - monitor daily and monthly consumption - send configurable notifications in case of abnormal use (overconsumption, etc.) Can be installed in place of an existing socket outlet in a flush-mounting box min. depth 35mm Indicator LED function can be activated from the Home + Control App.
1	5 742 56	<ul style="list-style-type: none"> <li>○ White</li> <li>● Magnesium</li> <li>● Champagne</li> <li>● Soft Alu</li> </ul>
1	5 742 58	
1	5 742 59	
1	5 742 57	
		<b>2P+E switched - 1-gang</b> Mechanisms supplied with cover plates and support frames, to be equipped with British standard plates 3 modules, 1-gang (see opposite)
1	5 742 66	<ul style="list-style-type: none"> <li>○ White</li> <li>● Magnesium</li> <li>● Champagne</li> <li>● Soft Alu</li> </ul>
1	5 742 68	
1	5 742 69	
1	5 742 67	

### British standard plates - 3 modules - 1-gang

Pack	Cat.Nos	Description
		<b>Suitable for 1-gang 2P+E connected British standard socket outlets</b>
5	5 751 60	<ul style="list-style-type: none"> <li>○ White</li> <li>● Soft Alu</li> <li>● Graphite</li> <li>● Magnesium</li> <li>● Champagne</li> <li>● Dark Bronze</li> <li>● Mirror White</li> <li>● Mirror Black</li> <li>● Brushed Metal - Stainless Steel</li> <li>● Brushed Metal - Gold Brass</li> <li>● Brushed Metal - Pink Champagne</li> <li>● Brushed Metal - Black</li> <li>● Reflective Metal - Stainless Steel</li> <li>● Reflective Metal - Black</li> <li>● Reflective Metal - Gold</li> <li>● Wood - Grey Oak</li> <li>● Signature - Cube</li> </ul>
5	5 713 03	
5	5 751 62	
5	5 713 13	
5	5 713 23	
5	5 713 33	
1	5 751 64	
1	5 751 63	
1	5 751 66	
1	5 761 80	
1	5 713 53	
1	5 713 43	
1	5 713 63	
1	5 713 83	
1	5 713 73	
1	5 713 93	
1	5 714 03	

### British standard plates - 2x3 modules - 2-gang

Pack	Cat.Nos	Description
		<b>Special plates for 2-gang connected British standard socket outlets</b>
1	5 712 10	<ul style="list-style-type: none"> <li>○ White</li> <li>● Soft Alu</li> <li>● Graphite</li> <li>● Magnesium</li> <li>● Champagne</li> <li>● Dark Bronze</li> <li>● Mirror White</li> <li>● Mirror Black</li> <li>● Brushed Metal - Stainless Steel</li> <li>● Brushed Metal - Gold Brass</li> <li>● Brushed Metal - Pink Champagne</li> <li>● Brushed Metal - Black</li> <li>● Reflective Metal - Stainless Steel</li> <li>● Reflective Metal - Black</li> <li>● Reflective Metal - Gold</li> <li>● Wood - Grey Oak</li> <li>● Signature - Cube</li> </ul>
1	5 712 11	
1	5 712 12	
1	5 712 13	
1	5 712 14	
1	5 712 15	
1	5 712 16	
1	5 712 17	
1	5 712 18	
1	5 712 19	
1	5 712 20	
1	5 712 21	
1	5 712 22	
1	5 712 23	
1	5 712 24	
1	5 712 25	
1	5 712 26	