


# Universal box and flush-mounting boxes for masonry

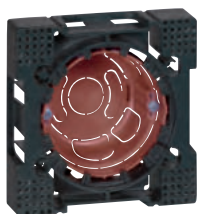

 




0 801 08 + 0 778 83







0 801 41



2 x 0 801 08 (back to back joining)

Pack	Cat.Nos	Universal 1-gang box
250	0 313 01	<p>For screw or claw mounting Supplied without screws Can be used with Arteur, Galea Life, Mosaic, Vela, Valena, Niloé and Kaptika ranges, Horizontal and vertical mounting 1-gang unit Can be fitted alongside one another Can be used as junction box with cover Cat.No 0 892 81</p> 
10	0 801 40 <sup>1</sup>	<p><b>1-gang boxes for masonry</b> <b>For 1 module</b> Depth 40 mm - Width 32 mm</p> <p><b>Square boxes for joining together</b> For wiring accessories using screws or claws 1-gang boxes can be used to make up multi-gang boxes by joining Can be used horizontally or vertically 71 mm fixing centres Cutting out of internal partitions for mounting extended functions Supplied with screws fitted with protective shield Knockout cable entries, Ø16-20-25</p> 
100	0 801 41 <sup>1</sup>	<p>Depth 40 mm</p> 
100	0 801 51 <sup>1</sup>	
100	0 801 08 <sup>1</sup>	<p><b>Round for joining together back to back</b> Upper flange can be cut to obtain a depth of 30 mm (for controls, 2-way switches, push-buttons, etc.) Boxes can be joined back to back by 1/4 of a turn Adjustable dimensions (80, 70 or 60 mm) by cutting the flange With screws</p>  <p>Depth 40 mm - Ø67 mm</p>
10	0 801 49	<p><b>Multi-gang boxes for masonry</b> <b>Batibox</b> For 3 module Arteur, Vela, Mosaic ranges Supplied with screws Depth 40 mm Knockout cable entries, Ø16-20-25</p> 
15	0 892 39	<p><b>Italian type boxes for masonry</b> For screw or claw mounting devices Arteur, Mosaic, Vela ranges Supplied without screws Horizontal mounting Depth 50 mm</p>
5	0 892 49	
1	0 892 50	

Pack	Cat.Nos	Multi-gang boxes for multi-material
1	0 801 24	<p>For Arteur, Mosaic Depth 50 mm 2 x 2 gang or 2 x 4/5 modules Dimensions: 142 x 142 mm 2 x 3 gang or 2 x 6/8 modules Dimensions: 213 x 142 mm 2 x 10 modules Dimensions: 284 x 142 mm</p>
1	0 801 26	
1	0 801 28	
5	0 801 85	<p><b>Box for 20 A and 32 A sockets</b> <b>1-gang 85 x 85 mm</b> For cable outlets Cat.No 0 314 90, 20 A sockets and 32 A sockets Depth 50 mm Vertical positioning of the screws for fixing 20 A and 32 A sockets</p> 
5	0 801 55	<p><b>Box for shaver socket</b> For Mosaic shaver socket Cat.No 0 775 86 (p. 1181), and Arteur shaver sockets (p. 591) Depth 50 mm</p> 
50	0 892 46	<p><b>Luminaire box with cover</b> <b>For striplights</b> Ø40 mm - depth 40 mm</p> 
20	0 801 80	<p><b>Universal covers</b> For converting wiring devices boxes into junction boxes or for closing up an existing box Supplied without fixing screws For one-gang or multi-gang boxes Round cover, Ø85 mm, for 1-gang box</p> 
20	0 892 81	
10	0 801 82	

<sup>1</sup>: Box made from plastic material from the recycling of electrical products and post-consumer waste