 


Rigid conduits



6 514 16



0 319 06



0 319 00



0 313 82



0 313 83



Conduit supports installation p. 815

Pack	Cat.Nos	Medium impact rigid conduits with integrated coupling															
		<p>PVC without Pb, Sn, Cd (RoHS compliant) Non flame propagating Surface-mounting or flush-mounting Suitable for prefabricated concrete Conforming to European standard: EN/IEC 61386-21 Crush resistance: 750 Newtons Impact resistance: 2 joules at - 5 °C Min operating t°: - 5 °C Max operating t°: + 60 °C IK 07 Can be used outside Supplied wrapped in film. Light grey (RAL 7035) Length of tubes: 3 m</p>															
		<table border="1"> <thead> <tr> <th>ø exterior (mm)</th> <th>ø interior (mm)</th> <th>thickness (mm)</th> </tr> </thead> <tbody> <tr> <td>16</td> <td>13</td> <td>1.50</td> </tr> <tr> <td>20</td> <td>16.9</td> <td>1.55</td> </tr> <tr> <td>25</td> <td>21.4</td> <td>1.80</td> </tr> <tr> <td>32</td> <td>27.8</td> <td>2.10</td> </tr> </tbody> </table>	ø exterior (mm)	ø interior (mm)	thickness (mm)	16	13	1.50	20	16.9	1.55	25	21.4	1.80	32	27.8	2.10
ø exterior (mm)	ø interior (mm)	thickness (mm)															
16	13	1.50															
20	16.9	1.55															
25	21.4	1.80															
32	27.8	2.10															
30	6 514 16																
30	6 514 20																
30	6 514 25																
15	6 514 32																

Pack	Cat.Nos	Clipsotubes	Ø mini (mm)	Ø maxi (mm)
		<p>Fixing by Ø7 mm thread 150 mm pin, screw-in wall plugs Cat.No 0 319 57, screw Ø5 mm or nail For interior use Holding of flexible and rigid conduits</p>		
		<p>Grey RAL 7035</p>		
100	0 319 03	For IRL Ø16 mm	15	16
100	0 319 04	For IRL Ø20 mm	18.4	20.6
100	0 319 06	For IRL Ø25 mm	22.3	25

Pack	Cat.Nos	Cable ties with base
		<p>Adjustable for conduits IRL Ø16 to 32 mm or for cable Ø13 to 38 mm Fixing by Ø7 mm thread 150 mm pin, screw in wall plugs Cat.No 0 319 57, screw Ø5 mm Can be fixed using Pulsa 700 E staple gun For interior and exterior use - U.V. protected Black colour</p>
100	0 319 02	For interior use - Light grey RAL 7035
1000	0 319 00	

Pack	Cat.Nos	Conduit supports with screw-in wall plug
		<p>Conduit supports For conduit Ø16 For conduit Ø20 For conduit Ø25</p>
100	0 313 80	
100	0 313 81	
50	0 313 82	
		<p>Conduit supports accessory For fixing in plasterboard plate</p>
200	0 313 83	

Accessories for flexible and rigid conduits



060 01



6 516 09



6 516 11




6 516 18




6 516 32

Light grey (RAL 7035)


Pack	Cat.Nos	Couplings
		For connecting conduits of the same diameter
100	060 01	Ø16 mm
100	060 02	Ø20 mm
50	060 03	Ø25 mm
25	060 04	Ø32 mm




Pack	Cat.Nos	Reducers
		For connecting conduits of different diameters
50	6 516 09	Ø25 x 20 mm




Pack	Cat.Nos	Elbows
		Used to change direction even after the wires have been installed. 2-part assembly to save time and simplify installation
50	6 516 11	Ø16 mm
50	6 516 12	Ø20 mm
25	6 516 13	Ø25 mm



Pack	Cat.Nos	Tees
		Used to join conduits together and to change direction even after the wires have been installed
50	6 516 18	Ø16 mm
25	6 516 19	Ø20 mm
25	6 516 20	Ø25 mm



Pack	Cat.Nos	Bends
		90° curves
20	060 42	Ø20 mm - length: 130 mm
10	060 43	Ø25 mm - length: 160 mm
25	060 44	Ø32 mm - length: 200 mm

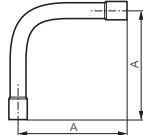

Pack	Cat.Nos	Bending springs								
		Used to bend rigid conduits								
		<table border="1"> <thead> <tr> <th>Ø (mm)</th> <th>Length (mm)</th> </tr> </thead> <tbody> <tr> <td>16</td> <td>600</td> </tr> <tr> <td>20</td> <td>800</td> </tr> <tr> <td>25</td> <td>800</td> </tr> </tbody> </table>	Ø (mm)	Length (mm)	16	600	20	800	25	800
Ø (mm)	Length (mm)									
16	600									
20	800									
25	800									
1	6 516 32									
1	6 516 33									
1	6 516 34									

Pack	Cat.Nos	Nylon draw tape
		Flexible cable which can be used to guide the wires into an unwired conduit. 2 metal end caps End cap diameter: 6 mm at both ends for attaching the wires Length: 20 m
1	060 82	