


Special plugs with sockets

German standard



Pack	Cat.Nos	2P+E + 2 x RJ 45 socket with voltage surge protector
8	6 946 70	Protection of electrical and electronic devices and the telephone circuit against lightning and overvoltages With indicator showing the status of the voltage surge protector ADSL compatible RJ 45/RJ 11 I/O: Uc: 200 V, Uoc: 2 kV and Up: 600 V Supplied with 1.5 m RJ 11 cord

Pack	Cat.Nos	Plug with 2P+E 16 A socket - 250 V~
8	0 504 62	Wires onto a cord connected to a device, enabling a second device to be connected to the same socket Plug 16 A/250V - 3680 W To be connected to a flexible cord 3G 1.5 mm ²

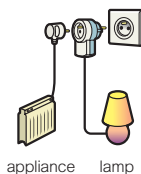

Pack	Cat.Nos	Plug with switch, 16 A - 250 V~
8	0 504 09	For fitting on a class I domestic appliance Equipped with an on/off switch Well adapted for appliance or multioutlet extensions non-equipped with an on/off button Plug 16A / 250V – 3680W To be connected to a 3G 1.5mm ² flexible cord



Spotlights, dimmable night lamps and night light



Pack	Cat.Nos	Spotlights with battery
12	0 506 78	Equipped with 2 high luminosity LED lamps (warm light/ cold light) Light intensity can be adjusted by keeping the lens pressed, if used as spotlight Can be removed and used as a torch in case of emergency Battery life: minimum 1.5 hours Turn on automatically to maximum intensity of cold light in case of black-out ○ White

Pack	Cat.Nos	Dimmable night lamps
12	0 506 76	High luminosity LED spotlights to be used in either auto mode (day/night automatic sensor) or manual mode (on/off switching) Light intensity can be adjusted by keeping the lens pressed ○ White
12	0 506 77	● Black

Pack	Cat.Nos	Night light with LED with light-sensitive sensor, 230 V
8	0 506 73	Automatic lighting thanks to sensitive sensor (day/night) LED spotlight technology Supplied with 4 solid-coloured labels and 1 customisable paper label



See the video on spotlights benefits



See the video on dimmable night lamp benefits

