





## Single-socket plugs

### British standard

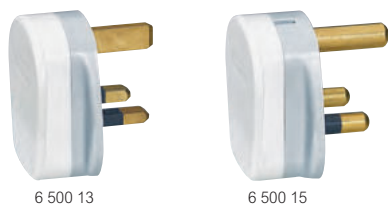

6 500 13

6 500 15

Pack	Cat.Nos	British standard plugs
20	6 500 13	 White  13 A - 250 V $\sim$ - 2P+ $\perp$ With integrated fuse for protection against overloads
20	6 500 15	 15 A - 250 V $\sim$ - 2P+ $\perp$

## Multi-socket plugs and extensions

### German standard



0 504 90



3 902 33



0 503 77

Pack	Cat.Nos	2P+E multi-socket plug - 16 A - rubber
5	Gencod labelling 0 504 90	Max. admissible power 3.680 W at 230 V $\sim$ <b>2 front outlets - shockproof IK 08</b> Rubber multi-socket plug with caps - IP 44 ● Black
		<b>2P+E extension leads</b> With shutters to allow easy insert of the plug in the socket and to ensure safety 2P+E ergonomic socket with easy disconnection H05 VVF 3G 1.5 mm <sup>2</sup> cord Supplied with plastic hook for hanging with Gencod
10	3 902 33	<b>3 m length</b> ○ White
10	3 900 86	<b>5 m length</b> ○ White
5	3 902 34	<b>10 m length</b> ○ White
5	0 503 77	<b>Multi-socket "octopus" extension leads ready to use - rubber</b> ● Black - 2P+E - 16 A - IK 10 With 1 plug and 3 extensions H07 RNF 3G 1.5 and 2.5 mm <sup>2</sup> cable Length: 0.8 m