

Multi-outlet extensions with cord

British standard



6 985 04



6 985 30

To connect several devices equipped with plugs with or without earth: appliances class I (simple insulation) or class II (double insulation), lamps, PC, TV, stereo, etc.

Extra-flat (only 30 mm thick): can be slid underneath furniture


Pack	Cat.Nos	Multi-outlet extensions
		<p>Conform to BS 1363-2 - ASTA certification </p> <p>Sockets equipped with shutter for child protection Can be wall, desk or floor mounted thanks to key holes at the back Flame-retardant material (up to 850 °C) Overload protection by fuse (integrated in plug) Power supply cord 3m or 5m 13 A max. Power: 3250 W at 250 V - 50/60 Hz</p> <p>3 m cord – with one switch per extension cord On/Off double pole safety switch, with light indicator SASO 2815 certification Resettable MCB. Cord 1,5 mm² section</p> <p>10 6 985 24 4 x 2P+E 10 6 985 25 5 x 2P+E 10 6 985 26 6 x 2P+E</p> <p>3 m cord – with one switch per socket On/Off single pole power switch, with light indicator ECAS certification</p> <p>10 6 985 04 4 x 2P+E 10 6 985 05 5 x 2P+E</p> <p>5 m cord – with one switch per extension cord On/Off double pole safety switch, with light indicator SASO certification Resettable MCB. Cord 1,5 mm² section</p> <p>10 6 985 34 4 x 2P+E 10 6 985 35 5 x 2P+E 10 6 985 36 6 x 2P+E</p> <p>5 m cord – with one switch per socket On/Off single pole power switch, with light indicator ECAS certification</p> <p>10 6 985 14 4 x 2P+E 10 6 985 15 5 x 2P+E</p>
		<p>Multi-outlet extensions with 2 USB Type-A sockets - 2.4 A 12 W total</p> <p>3 m – with one switch per extension cord On/Off double pole safety switch, with light indicator SASO certification</p> <p>10 6 985 30 4 x 2P+E White/Grey 10 6 985 32 4 x 2P+E Black</p> <p>5 m – with one switch per extension cord On/Off double pole safety switch, with light indicator SASO certification</p> <p>10 6 985 31 4 x 2P+E White/Grey</p> <p>3 m – with one switch per socket On/Off single pole power switch, with light indicator ECAS certification</p> <p>10 6 985 20 4 x 2P+E White/Grey</p> <p>5 m – with one switch per socket On/Off single pole power switch, with light indicator ECAS certification</p> <p>10 6 985 21 4 x 2P+E White/Grey</p>

Multi-outlet extensions with cord


Multi-standard



6 985 44

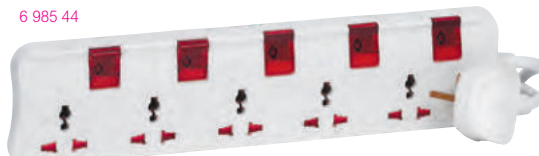

6 985 45

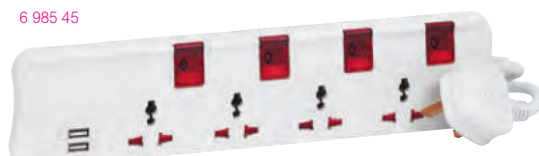

6 985 00

To connect several devices equipped with plugs with or without earth: appliances class I (simple insulation) or class II (double insulation), lamps, PC, TV, stereo, etc.

Extra-flat (only 30 mm thick): can be slid underneath furniture

Pack	Cat.Nos	Multi-standard multi-outlet extensions
		<p>Can receive different type of standard plugs : US, British, EU...</p> <p>Sockets equipped with: - shutters to ensure safety - 1 switch per socket Extra flat (only 30 mm thick) can be slid underneath furniture Can be wall, desk or floor-mounted thanks to key holes at the back Flame-retardant material (up to 850 °C) Overload protection by fuse (integrated in plugs) Power supply cord 3m or 5m, with 1.25 mm² section 13 A max. Power: 3250W at 250 V - 50/60 Hz</p> <p>3 m cord 4 x 2P+E 5 x 2P+E</p> <p>5 m cord 4 x 2P+E 5 x 2P+E</p>
		<p>Multi-outlet extensions with 2 USB Type-A sockets - 2.4 A 12 W total</p> <p>3 m White/Grey Black</p> <p>5 m White/Grey</p>