

## Radio wireless chimes




0 942 53



0 942 54



0 942 71

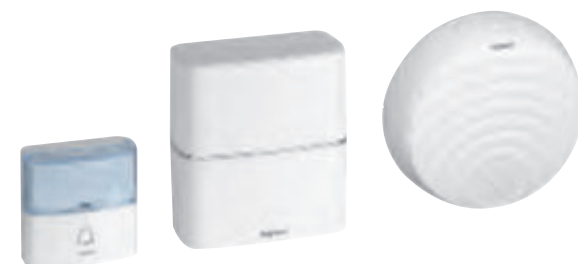

0 942 72



0 942 78



0 942 79

Pack	Cat.Nos	Radio chime kits
1	0 942 50	<b>Essential kit</b> Includes a chime and an IP 44 door bell with label holder Sound level: +/- 80 dB Number of ringtones: 32 Range approximately 50 m in free field Power supply: - chime: 2 x 1.5 V AA batteries (not included) - door bell: 1 CR2032 battery (included) White <b>Comfort kits</b> Includes a round chime and a round IP 44 door bell with label holder Sound level: +/- 75 dB. Volume control Number of ringtones: 15 Range approximately 100 m in free field Unlimited number of additional chimes for 1 door bell Power supply: - chime: 3 x 1.5 V AA batteries (not included) except Cat.No 0 942 54 (plug-in 230 V) - door bell: 1 CR2032 battery (included) 0 942 52 White - battery-operated 0 942 53 Anthracite - battery-operated 0 942 54 White - plug-in 230 V <b>Serenity kits</b> Includes a square chime and a square IP 54 door bell with label holder Sound level: +/- 80 dB. Volume control Number of ringtones: 30 Ringtone customised via MP3 (software for creating MP3 melody provided in chime internal memory + USB cable included) Chime mute function Built-in flash Range approximately 200 m in free field Unlimited number of additional chimes for 1 door bell Light signal on the chime to signal low battery level Power supply: - chime: 3 x 1.5V AA batteries (not included) - door bell: 1 CR2032 battery (included) 0 942 70 White - single battery-operated kit 0 942 71 Aluminium - single battery-operated kit 0 942 72 White - twin battery-operated kit. Includes a Serenity chime and a plug-in Comfort chime. Ideal, for example, for having one chime on the ground floor and one upstairs

Pack	Cat.Nos	Accessories for Comfort and Serenity radio chime kits
		White finish
1	0 942 78	<b>Comfort door bell - IP 44</b> Radio signal range 100 m Powered by 1 CR2032 battery (included)
1	0 942 79	<b>Serenity door bell - IP 54</b> Radio signal range 100 m Powered by 1 CR2032 battery (included)
1	0 942 80	<b>Motion detector - IP 20</b> Tilttable bracket for fixing on the wall or putting on a surface Radio signal range 150 m Detection range: 6-8 m Detection angle: 110° Powered by 3 x 1.5 V AAA batteries (not included)