


Smart home

connected thermostat

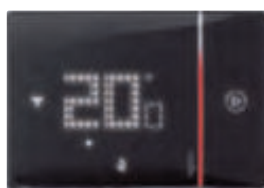

0 490 38



0 490 39



Home + Control

Pack	Cat.Nos	
		<p>Smarter with Netatmo connected thermostat</p> <p>The Smarter with Netatmo together with the Home + Control app allows to adjust and monitor the temperature and humidity measured in the rooms. It can combine comfort and energy savings on a daily basis.</p> <p>With Wi-Fi connection all the functions can be controlled locally or remotely via the Home + Control app or using your voice assistant (Google Home, Amazon Alexa and Apple Homekit).</p> <p>Works with all types of individual boiler (gas, oil or wood-fired boilers) and with heat pumps.</p> <p>The temperature level can be set locally for manual operation and the Boost mode allows to force the switching on of the system for a limited time (30, 60 or 90 minutes) independent of the measured and programmed temperature.</p> <p>Can be used in conjunction with Additional Smart Radiator Valves Cat.No NA-NAV-PRO (please consult us).</p> <p>Range up to 100 m (868 MHz)</p> <p>Measurement temperature: 0 C to 50 C, accuracy +/- 0.1 C</p> <p>Setpoint temperature: 5 C to 40C, with +/- 0.5 C adjustment</p> <p>Compatible with Wi-Fi 802.11 b/g/n (2.4 GHz)</p> <p>Security supported: WEP/WPA/WPA-2 personal (TKIP and AES)</p> <p>230 V~ mains supply</p> <p>2 modules</p> <p>Flush-mounting</p> <p>1 ON/OFF control output: 230 V~, volt-free contact, low-voltage contact, valves (4 A - 256 V~ max.)</p> <p>For installation in flush-mounting box with 1 gang depth 40 mm minimum</p> <p>1 0 490 38 ○ White</p> <p>1 0 490 39 ● Black</p> <p>Surface-mounting</p> <p>2 ON/OFF control outputs: 230 V~, volt-free contact, low-voltage contact, valves (4 A - 256 V~ max.) for simultaneous management of summer/winter modes</p> <p>For installation on the wall, using screws and dowels suitable for the surface installation (brickwork, plasterboard, tiles etc.)</p> <p>1 0 490 40 ○ White</p>



Products to be submitted to local tests to ensure a perfect functioning. Please contact your local agency.



Home + Control App. for the management of connected devices available on Google Play and App Store



Red catalogue numbers: New products

Smart home

connected thermostat for air conditioning and accessories



0 490 43



0 490 44



Home + Control

Compatible with Zigbee 3.0

Pack	Cat.Nos	
		<p>Smarter AC with Netatmo Connected Thermostat for air conditioning</p> <p>The Smarter AC with Netatmo together with the Home + Control app allows to adjust and monitor the temperature, humidity and fan speed for cooling mode in the rooms.</p> <p>With Wi-Fi connection all the functions can be controlled locally or remotely via the Home + Control app or using your voice assistant (Google Home, Amazon Alexa and Apple Homekit).</p> <p>The temperature level can be set locally for manual operation and the Boost mode allows to force the switching on of the system for a limited time (15, 30 or 45 minutes) independent of the measured and programmed temperature.</p> <p>IR range: 5 m</p> <p>Measurement temperature: 5 C to 40 C</p> <p>Setpoint temperature: 5 C to 40 C, with +/- 0.5 C adjustment (depending on the split)</p> <p>Compatible with Wi-Fi 802.11 b/g/n (2.4 GHz)</p> <p>Security supported: WEP/WPA/WPA-2 personal (TKIP and AES)</p> <p>110-240 VA</p> <p>2 modules</p> <p>Flush-mounting</p> <p>1 ON/OFF control output: 230 V~, volt-free contact, low-voltage contact, valves (4 A - 256 V~ max.). For installation in flush-mounting box with 1 gang depth 40 mm minimum</p> <p>1 0 490 43 ○ White</p> <p>1 0 490 44 ● Black</p> <p>Surface-mounting</p> <p>2 ON/OFF control outputs: 230 V~, volt-free contact, low-voltage contact, valves (4 A - 256 V~ max.) for simultaneous management of summer/winter modes</p> <p>For installation on the wall, using screws and dowels suitable for the surface installation (brickwork, plasterboard, tiles etc.)</p> <p>1 0 490 45 ○ White</p>
1	BT-3460IR	<p>IR interface for air conditioning unit</p> <p>Zigbee micromodule to be connected to the split to make the air conditioning compatible with the Smarter with Netatmo air conditioning controller.</p> <p>It communicates with Smarter AC through RF 2.4 GHz: thanks to its features, the emitter can be placed on the receiver of the A/C unit, ensuring perfect communication.</p> <p>Supplied with 1.5 m cord</p> <p>Power supply: 5 - 12 V and 110 - 240 V</p> <p>Dimensions: 60 x 60 x 30 mm</p> <p>Actuator for fan coil unit</p> <p>Can be used in combination with Smarter AC with Netatmo on thermoregulation installations, to control different load types according to requirements.</p> <p>0 489 10</p>