

# Practibox S Multimedia Home network cabinet



# Home network cabinet

## components




1 357 02



1 358 02

Selection chart p. 872

Pack	Cat.Nos	<b>Practibox S Multimedia Home network cabinets</b>
1	1 357 02	<b>Flush-mounting version</b> Supplied with white door 12-module width For bricks and masonry walls For dry partitions
1	1 357 22	
1	1 358 02	<b>Surface-mounting version</b> Supplied with white door 12-module width

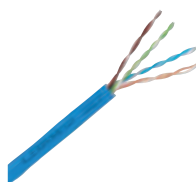

0 327 54



0 765 61



0 786 14

Selection chart p. 872

Pack	Cat.Nos	<b>RJ 45 sockets for datacom</b>
		Contacts marked with dual colour code for wiring schemes T568A and T568B Conforms to standards ISO/IEC 11801 Ed. 3.0, amendment 2, EN 50173-A and TIA/EIA 568 C
		<b>Cat. 6 UTP - 1 module</b> White
10	0 765 61	Mosaic version Arteor version
10	5 723 02	
		<b>Cat. 6 UTP - 2 modules</b> White
10	0 765 64	Mosaic version Arteor version
10	5 723 14	
		<b>Ethernet cables</b> Cables for local network cat. 6 U/UTP 4 twist pairs 100 Ω Blue RAL 5015 Colour code TIA/EIA Conform to standards ISO/IEC 11801 edition 2.0, EN 50173-1 and TIA/EIA 568C
305 <sup>(1)</sup>	0 327 54	<b>LSZH</b> Length 305 m Supplied in cardboard box Weight 16 kg Length 500 m Supplied on reel Weight 18 kg
505 <sup>(1)</sup>	0 328 61	
305 <sup>(1)</sup>	0 327 55	<b>PVC</b> Length 305 m Supplied in cardboard box Weight 13 kg
		<b>Optical socket for datacom</b> For connecting 2 fibres to the workstation Equipped with 1 duplex adaptor Supplied with protective caps
1	White 0 786 14	Mosaic version SC/APC single mode fiber optic socket

1: In meter(s)