

# Keor SPE tower version

Line Interactive UPS - Single phase VI-SS



# Keor SPE tower version

technical characteristics



3 110 60

- Power Factor: 0.8
- User friendly LCD display
- Wide input voltage range and frequency
- Hot swappable battery
- Programmable extended quantity of outlets
- Overload, short circuit, back-feed, overtemperature protection
- Powerful built-in charger
- Cold start (DC power on)
- RS232 & USB - SNMP Slot
- EPO (Emergency Power Off)
- 2 dry contacts
- Compact size & light weight


Pack	Cat.Nos	UPS		Back-up time (min)	Weight (kg)	Communication ports/slot
1	3 110 60	Nominal power (VA)	Active power (W)	9	6 / -	USB - RS232 - SNMP
1	3 110 61	750	600	7	8 / -	USB - RS232 - SNMP
1	3 110 62	1000	800	7	8 / -	USB - RS232 - SNMP
1	3 110 63	1500	1200	7	8 / -	USB - RS232 - SNMP
1	3 110 64	2000	1600	7	8 / -	USB - RS232 - SNMP
1	3 110 64	3000	2400	4	8 / 1	USB - RS232 - SNMP

		Accessories	
1	3 110 78	10 A British Standard cable for Cat.Nos 3 110 60/61/62	
1	3 110 79	16 A British Standard cable for Cat.Nos 3 110 63/64	


NOTE: The stated back-up times in minutes are estimated and may vary according to the load characteristics, operating conditions and environment

## Equipment

### Keor SPE 750 - 1000 VA

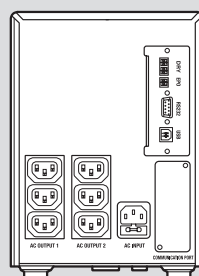


3 110 60

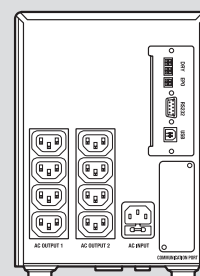


3 110 61


### Keor SPE 1500 - 2000 - 3000 VA

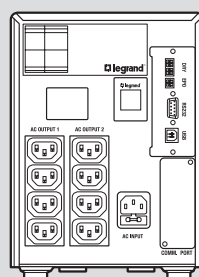

3 110 62

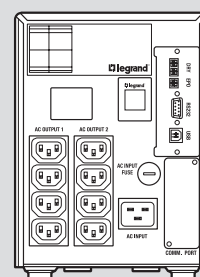

3 110 63

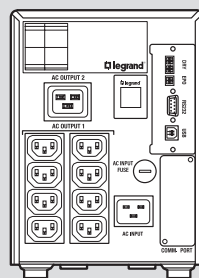

3 110 64