


LINKEO C - structured cabling solutions

patch panels, keystone, surface-mounting box and socket outlets

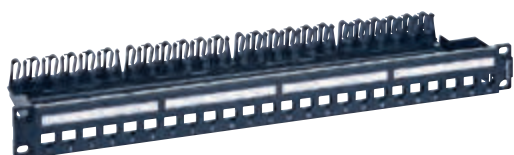

6 328 50



6 329 05



6 329 08



6 329 11



6 327 95



6 327 79



6 329 01

Pack	Cat.Nos	Patch panel to be equipped
1	6 328 50	Empty patch panel for 24 keystone connectors cat. 6 _A , cat. 6 or cat. 5e with metal cable holder To be equipped with RJ 45 connectors
		Keystone connectors
		Set of 24 RJ 45 connectors Keystone toolless RJ 45 connector Accepts from AWG 23 to AWG 26 solid and stranded conductors Contacts marked with dual colour code for wiring schemes T 568 A and T 568 B Conforms to standards ISO/IEC 11801 series ANSI/TIA 568 series EN 50173 series
		Cat. 6_A RJ 45 connectors
24	6 329 05	STP
24	6 329 06	UTP
		Cat. 6 RJ 45 connectors
24	6 329 07	STP
24	6 329 08	FTP
24	6 329 09	UTP
		Cat. 5e RJ 45 connectors
24	6 329 10	STP
24	6 329 11	UTP

Pack	Cat.Nos	Keystone faceplates
		RJ 45 Linkeo faceplates
14	6 327 94	1 port
14	6 327 95	2 ports
14	6 329 00	4 ports
		Angled RJ 45 Linkeo faceplates
14	6 327 96	1 port
14	6 327 97	2 ports
		Surface-mounting box
1	6 327 79	1 or 2 ports For keystone connectors Provides solution for integration of keystone in surface-mounting installations
		Socket outlet adaptors + RJ 45 connectors
		Set of 10 outlets (45 x 45 mm 2 modules, 1 port) and 10 RJ 45 connectors
10	6 329 01	With RJ 45 cat. 6 _A STP
10	6 329 02	With RJ 45 cat. 6 FTP
10	6 329 03	With RJ 45 cat. 6 UTP
10	6 329 04	With RJ 45 cat. 5e UTP
		Patch panel telephone 50 ports 110 connect
1	0 335 79	High density: supports 50 ports using 1 U of rack space Compatible with 22-26 AWG 19" panel - 1 U