

Linkeo 19" freestanding cabinets


cabinets and equipment



6 467 64



6 464 03

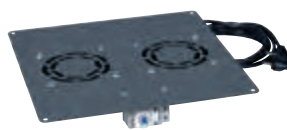

6 464 30



Technical characteristics **p. 944**

Pack	Cat.Nos		Linkeo 19" cabinets			
			IP 20 - IK 08 baying cabinets Reversible flat screen-printed safety glass door Removable side and rear panels with automatic equipotential bonding All 4 sides can be locked with a key Equipped with 2 x 19" uprights with U marking and adjustable depth Pre-cut cable entries (top and bottom) To be fitted with brush cable entry Cat.No 6 464 28 Cut-out at the top for fan kit Equipped with levelling feet Loading capacity: 400 kg Anthracite grey RAL 7016			
			Single front door			
	Ready-assembled	Flatpack	Capacity	Height (mm)	Width (mm)	Depth (mm)
1	6 467 50	6 467 75	24U	1226	600	600
1	6 467 51	6 467 76	24U	1226	800	800
1	6 467 55	6 467 80	33U	1626	600	600
1	6 467 56	6 467 81	33U	1626	800	800
1	6 467 60	6 467 85	42U	2026	600	600
1	6 467 61	6 467 86	42U	2026	600	800
1	6 467 62	6 467 87	42U	2026	600	1000
1	6 467 63	6 467 88	42U	2026	800	600
1	6 467 64	6 467 89	42U	2026	800	800
1	6 467 65	6 467 90	42U	2026	800	1000
1	6 467 73	6 467 98	47U	2248	800	800
1	6 467 74	6 467 99	47U	2248	800	1000
			Extension cabinet with single front door			
			No side panels			
			Supplied with baying kit			
1	6 467 70	6 467 95	42U	2026	800	800
			Double front door			
1	6 467 66		42U	2026	800	600
1	6 467 67		42U	2026	800	800
1	6 467 68		42U	2026	800	1000
			Linkeo baying kits			
1	6 463 37		For joining 2 x Linkeo 19" cabinets			
			Linkeo 19" uprights			
			Set of 2 additional 19" uprights			
1	6 463 40		24U			
1	6 463 41		33U			
1	6 463 42		42U			
1	6 463 43		47U			

Pack	Cat.Nos		Linkeo plinths			
			Metal plinths consisting of 4 corner blocks and 4 removable solid traps Height 100 mm Anthracite grey RAL 7016 For cabinets width x depth (mm):			
1	6 464 00		600 x 600			
1	6 464 01		600 x 800 or 800 x 600			
1	6 464 02		600 x 1000			
1	6 464 03		800 x 800			
1	6 464 04		800 x 1000			
			Casters			
1	0 464 82		Set of 4 pivoting casters, 2 of which have brakes			
			Total permissible load on the 4 casters: 500 kg			
			Linkeo fan kits			
			Integrated thermostat, adjustable from -10 to +80 °C			
			2.5 m power supply cord with 2P+E plug			
			230 V~			
			Anthracite grey RAL 7016			
1	6 464 30		2 fans			
1	6 464 31		4 fans			
			Linkeo cable management			
			Brush cable entry			
			To fit on top and bottom pre-cut cable entries			
			Set of brush seals			
1	6 464 28					
			Vertical cable trays			
			Side or rear mounting on structure			
1	6 464 20		For 33U cabinet			
1	6 464 21		For 42U cabinet			
1	6 464 22		For 47U cabinet			
			Cable management ring			
			For cabinet width 800 mm. Fixes onto 19" uprights			
1	6 464 25		Usable dim.: 65 x 145 mm. Black RAL 9005			
			Set of 6 metal rings			
			Vertical cable managers			
			For cabinet width 800 mm			
			Set of 2 vertical panels to manage cords at the front			
			along the whole height of the cabinet with brush feedthroughs and fingers for holding cords in place every 1U			
1	6 464 26		For 42U cabinets			
1	6 464 27		For 47U cabinets			
			PDU support			
			Mounted at the back of the cabinet			
			For vertical mounting of 19" and Zero-U PDUs			
1	6 464 15		For 42U cabinets			
1	6 464 16		For 47U cabinets			



For overall cabinet dimensions, **see p. 947 to 949**