


Legrand cabling system, LCS³ cat. 6_A and cat. 7

cables and cords

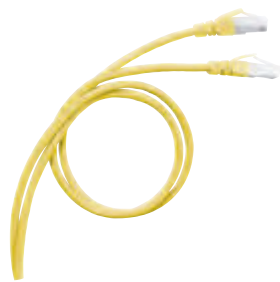

0 327 77



0 517 82



Easy grip

Pack	Cat.Nos	Cat. 6 _A cables for local networks
		Performance 500 MHz 4 twisted pair cables, 100 Ω LSZH sheath: zero halogen ANSI/TIA colour code Compliant with ISO/IEC 11 801, EN 50173 and ANSI/TIA 568 standards Products conforming to the CPR regulations
		U/UTP - 4 pairs
500 ¹	0 327 87	Length 500 m. Supplied on reel. Weight 35 kg Euroclass Dca
500 ¹	0 328 28	Length 500m. Supplied on reel. Weight 36 kg Euroclass Cca
500 ¹	0 328 38	Length 500m. Supplied on reel. Weight 33 kg Euroclass B2ca
		F/UTP - 4 pairs
500 ¹	0 327 78	Length 500 m. Supplied on reel. Weight 29.2 kg Euroclass Dca
		F/UTP - 2 x 4 pairs
500 ¹	0 328 78	Length 500 m. Supplied on reel. Weight 58 kg Euroclass Dca
		F/FTP - 4 pairs
500 ¹	0 328 83	Length 500 m. Supplied on reel. Weight 32 kg Euroclass Cca
500 ¹	0 327 99	Length 500 m. Supplied on reel. Weight 26 kg Euroclass Dca
		F/FTP - 2 x 4 pairs
500 ¹	0 327 98	Length 500 m. Supplied on reel. Weight 62 kg Euroclass Dca
		U/FTP - 4 pairs
500 ¹	0 328 84	Length 500 m. Supplied on reel. Weight 39 kg Euroclass Cca

Pack	Cat.Nos	Cat. 7 cables for local networks
		Performance 600 MHz 4 twisted pair cables, 100 Ω LSZH sheath: zero halogen ANSI/TIA colour code Compliant with ISO/IEC 11 801 and EN 50173 standards Products conforming to the CPR regulations
		S/FTP - 4 pairs
500 ¹	0 328 82	Length 500 m. Supplied on reel. Weight 33 kg Euroclass B2 ca
500 ¹	0 328 49	Length 500m. Supplied on reel. Weight 31 kg Euroclass Cca
500 ¹	0 327 77	Length 500 m. Supplied on reel. Weight 30 kg Euroclass Dca
		S/FTP - 2 x 4 pairs
500 ¹	0 327 79	Length 500 m. Supplied on reel. Weight 63 kg Euroclass Dca

Pack	Cat.Nos	Cat. 7 indoor/outdoor cable for local networks
		Performance 600 MHz 4 twisted pair cable, 100 Ω LSZH sheath: zero halogen ANSI/TIA colour code Compliant with ISO/IEC 11 801 and EN 50173 standards Product conforming to the CPR regulations
		S/FTP - 4 pairs - indoor/outdoor
500 ¹	0 338 90	Length 500 m. Supplied on reel. Weight 26 kg Euroclass Eca

Pack	Cat.Nos	Cat. 6 _A RJ 45 patch cords and user cords
		RJ 45/RJ 45 - flat With special "easy grip" plug Compliant with ISO/IEC 11 801, EN 50173 and ANSI/TIA 568 standards
		Unscreened U/UTP, impedance 100 Ω
		PVC
1	0 518 82	Length 1 m
1	0 518 83	Length 2 m
1	0 518 84	Length 3 m
1	0 518 85	Length 5 m
		LSZH
1	0 518 78	Length 1 m
1	0 518 79	Length 2 m
1	0 518 80	Length 3 m
1	0 518 81	Length 5 m
		PVC
1	0 518 74	Length 1 m
1	0 518 75	Length 2 m
1	0 518 76	Length 3 m
1	0 518 77	Length 5 m
		LSZH
		Shielded S/FTP, impedance 100 Ω
1	0 518 48	Length 0.3 m
1	0 518 16	Length 0.5 m
5	0 517 80	Length 1 m
5	0 517 81	Length 2 m
5	0 517 82	Length 3 m
5	0 517 83	Length 5 m
1	0 518 49	Length 10 m
		LSZH
1	0 518 70	Length 1 m
1	0 518 71	Length 2 m
1	0 518 72	Length 3 m
1	0 518 73	Length 5 m
		LSZH
1	0 518 66	Length 1 m
1	0 518 67	Length 2 m
1	0 518 68	Length 3 m
1	0 518 69	Length 5 m

Pack	Cat.Nos	Cat. 6 _A RJ 45 patch cords and user cords - High Density
		RJ 45/RJ 45 - flat With special "easy grip" plug Compliant with ISO/IEC 11 801, EN 50173 and ANSI/TIA 568 standards
		Shielded S/FTP, impedance 100 Ω
		LSZH
1	0 515 50	Length 0.5 m
1	0 515 51	Length 1 m
1	0 515 52	Length 2 m
1	0 515 53	Length 3 m
1	0 515 54	Length 5 m

Pack	Cat.Nos	Marking kit
200	0 518 90	Kit of 200 coloured rings for marking RJ 45 cords 4 colors (green/red/yellow/blue) 50 pieces of each color Rings to be clipped onto the patch cords 1: in metre(s)