



# Legrand cabling system, LCS<sup>3</sup> cat. 6

## cables and cords

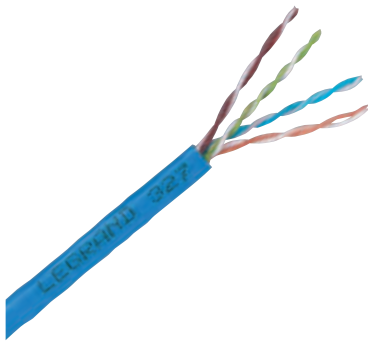

0 327 54

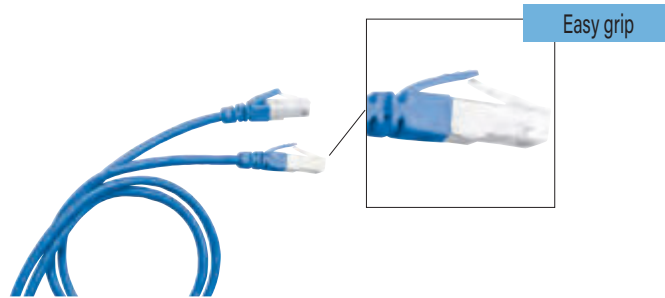

0 517 54



0 515 41

Pack	Cat.Nos	Cat. 6 cables for local networks
		Performance 250 MHz Cables with 4 pairs or 2 x 4 twisted pairs, 100 Ω Blue RAL 5015 ANSI/TIA colour code Compliant with ISO/IEC 11 801, EN 50173 and ANSI/TIA 568 standards Products conforming to the CPR regulations Euroclass Dca for LSZH cables (except Cat No 0 328 86: Euroclass Cca and Cat No 0 328 79 : Euroclass B2ca), Euroclass Eca for PVC cables
		<b>U/UTP - 4 pairs</b>
305 <sup>1</sup>	0 327 54	Length 305 m Supplied in cardboard box. Weight 14 kg
305 <sup>1</sup>	0 328 86	Length 305 m Supplied in cardboard box. Weight 15 kg
305 <sup>1</sup>	0 328 79	Length 500m Supplied on reel. Weight 24 kg
500 <sup>1</sup>	0 328 61	Length 500 m Supplied on reel. Weight 19 kg
305 <sup>1</sup>	0 327 55	Length 305 m Supplied in cardboard box. Weight 13 kg
		<b>F/UTP - 4 pairs</b>
305 <sup>1</sup>	0 328 56	Length 305 m Supplied in reel in box. Weight 19 kg
500 <sup>1</sup>	0 327 56	Length 500 m Supplied on reel. Weight 27 kg
		<b>F/UTP - 4 pairs</b>
305 <sup>1</sup>	0 328 57	Length 305 m Supplied in reel in box. Weight 20 kg
500 <sup>1</sup>	0 327 58	Length 500 m Supplied on reel. Weight 25 kg
		<b>F/UTP - 2 x 4 pairs</b>
500 <sup>1</sup>	0 327 76	Length 500 m Supplied on reel. Weight 51 kg
		<b>SF/UTP - 4 pairs</b>
500 <sup>1</sup>	0 327 57	Length 500 m Supplied on reel. Weight 31 kg
500 <sup>1</sup>	0 327 59	Length 500 m Supplied on reel. Weight 30 kg

1: in metre(s)

Pack	Cat.Nos	Cat. 6 RJ 45 patch cords and user cords
		RJ 45/RJ 45 - straight Compliant with ISO/IEC 11 801, EN 50173 and ANSI/TIA 568 standards
		<b>Shielded SF/UTP, impedance 100 Ω</b>
		Length 1 m
		Length 2 m
		Length 3 m
		Length 5 m
		<b>Screened F/UTP, impedance 100 Ω</b>
		Length 0.5 m
		Length 1 m
		Length 2 m
		Length 3 m
		Length 5 m
		<b>Unshielded U/UTP, impedance 100 Ω</b>
		Length 0.5 m
		Length 1 m
		Length 2 m
		Length 3 m
		Length 5 m
		<b>Cat. 6 RJ 45 patch cords and user cords - High Density</b>
		RJ 45/RJ 45 - straight Compliant with ISO/IEC 11 801, EN 50173 and ANSI/TIA 568 standards
		<b>Screened F/UTP, impedance 100 Ω</b>
		Length 0.5 m
		Length 1 m
		Length 2 m
		Length 3 m
		Length 5 m
		<b>Unshielded U/UTP impedance 100 Ω</b>
		Length 0.5 m
		Length 1 m
		Length 2 m
		Length 3 m
		Length 5 m

Pack	Cat.Nos	Cat. 6 RJ 45 patch cords and user cords - High Density
		RJ 45/RJ 45 - straight Compliant with ISO/IEC 11 801, EN 50173 and ANSI/TIA 568 standards
		<b>Screened F/UTP, impedance 100 Ω</b>
		Length 0.5 m
		Length 1 m
		Length 2 m
		Length 3 m
		Length 5 m
		<b>Unshielded U/UTP impedance 100 Ω</b>
		Length 0.5 m
		Length 1 m
		Length 2 m
		Length 3 m
		Length 5 m
		<b>Marking kit</b>
200	0 518 90	Kit of 200 coloured rings for marking RJ 45 cords 4 colors (green/red/yellow/blue) 50 pieces of each color Rings to be clipped onto the patch cords