


## Legrand cabling system, LCS<sup>3</sup> fiber optic

### Core™ fiber patch cords

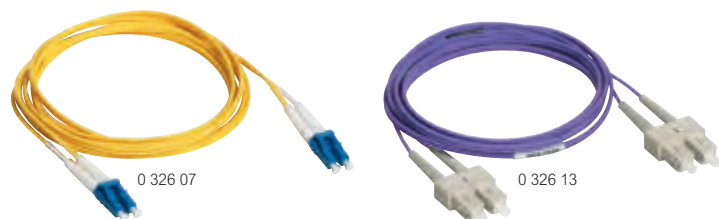

Selection chart p. 968-969

Fitted at each end with 2 connectors with ceramic ferrule  
Individually packed and tested (report supplied)  
Max. optical losses/Master: 0.25 dB  
LSZH Zipcord sheath

Pack	Cat.Nos	OS2 single-mode fiber optic cords (9/125 μm)
		For 9/125 μm single-mode installations, OS2 type Yellow sheaths
3	0 326 00	<b>SC/SC duplex cords</b> Length: 1 m
3	0 326 01	Length: 2 m
3	0 326 02	Length: 3 m
3	0 326 03	<b>SC/LC duplex cords</b> Length: 1 m
3	0 326 04	Length: 2 m
3	0 326 05	Length: 3 m
3	0 326 28	<b>LC/LC duplex cords</b> Length: 0.5 m
3	0 326 06	Length: 1 m
3	0 326 07	Length: 2 m
3	0 326 08	Length: 3 m
3	0 326 29	Length: 5 m
		<b>OM3 multimode fiber optic cords (50/125 μm)</b>
		For 50/125 μm multimode installations, OM3 type Aqua sheaths
3	0 326 09	<b>SC/SC duplex cords</b> Length: 1 m
3	0 326 10	Length: 2 m
3	0 326 11	Length: 3 m
3	0 326 12	<b>SC/LC duplex cords</b> Length: 1 m
3	0 326 13	Length: 2 m
3	0 326 14	Length: 3 m
3	0 326 15	<b>LC/LC duplex cords</b> Length: 1 m
3	0 326 16	Length: 2 m
3	0 326 17	Length: 3 m
		<b>OM4 multimode fiber optic cords (50/125 μm)</b>
		For 50/125 μm multimode installations, OM4 type Aqua sheaths
5	0 322 60	<b>SC/SC duplex cords</b> Length: 1 m
5	0 322 61	Length: 2 m
5	0 322 62	Length: 3 m
5	0 322 63	<b>SC/LC duplex cords</b> Length: 1 m
5	0 322 64	Length: 2 m
5	0 322 65	Length: 3 m
5	0 322 66	<b>LC/LC duplex cords</b> Length: 1 m
5	0 322 67	Length: 2 m
5	0 322 68	Length: 3 m

## Legrand cabling system, LCS<sup>3</sup> fiber optic

### Ultra™ fiber patch cords



Selection chart p. 968-969

Fitted at each end with 2 connectors with ceramic ferrule  
Individually packed and tested (report supplied)  
Max. optical losses/Master: 0.15 dB  
LSZH Zipcord sheath

Pack	Cat.Nos	OS2 single-mode fiber optic cords (9/125 μm)
		For 9/125 μm single-mode installations, OS2 type Yellow sheaths
5	0 325 27	<b>SC/SC duplex cords</b> Length: 1 m
5	0 325 28	Length: 2 m
5	0 325 29	Length: 3 m
5	0 325 30	<b>SC/LC duplex cords</b> Length: 1 m
5	0 325 31	Length: 2 m
5	0 325 32	Length: 3 m
5	0 325 33	<b>LC/LC duplex cords</b> Length: 1 m
5	0 325 34	Length: 2 m
5	0 325 35	Length: 3 m
5	0 325 36	Length: 5 m
		<b>LC/LC Uniboot duplex cords</b> Reversible polarity
3	0 326 86	Length: 1 m
3	0 326 87	Length: 2 m
3	0 326 88	Length: 3 m
3	0 326 89	Length: 5 m
3	0 326 92	Length: 10 m
		<b>OM4 multimode fiber optic cords (50/125 μm)</b>
		For 50/125 μm multimode installations, OM4 type Aqua sheaths
3	0 326 30	<b>SC/SC duplex cords</b> Length: 1 m
3	0 326 31	Length: 2 m
3	0 326 32	Length: 3 m
3	0 326 33	<b>LC/LC duplex cords</b> Length: 0.5 m
3	0 326 34	Length: 1 m
3	0 326 35	Length: 2 m
3	0 326 36	Length: 3 m
3	0 326 37	Length: 5 m
		<b>LC/LC Uniboot duplex cords</b> Reversible polarity
3	0 326 95	Length: 0.5 m
3	0 326 96	Length: 1 m
3	0 326 97	Length: 2 m
3	0 326 98	Length: 3 m
3	0 326 99	Length: 5 m