


Legrand cabling system LCS³ enclosures

accessories for server cabinets and cabling cabinets (continued)

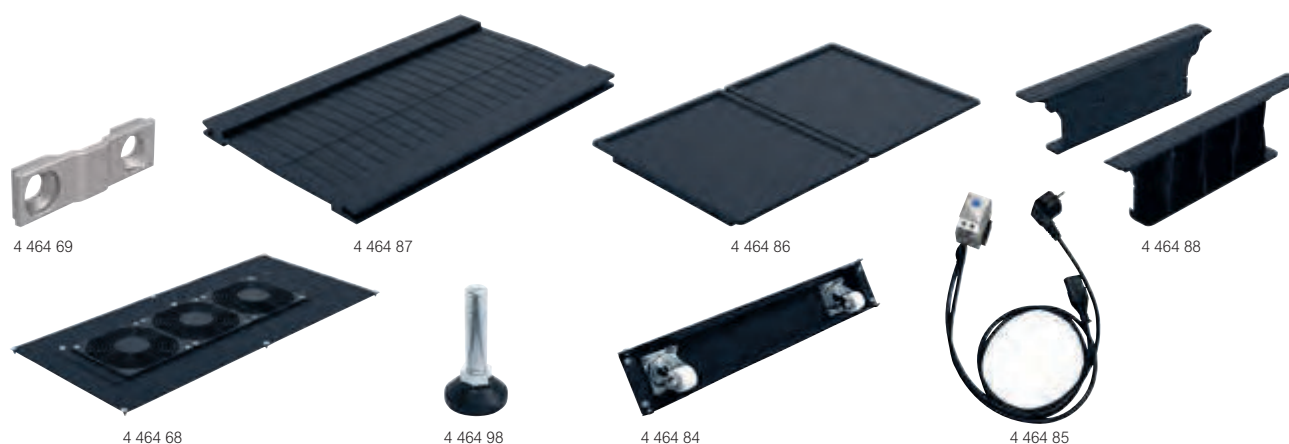

Pack	Cat.Nos	Mechanical accessories
6	4 464 69	Frame couplers To be used to connect two cabinets
1	4 464 87	Roof brushes Roof brush to be installed on right/left roof cut-outs Depth 200 mm
1	4 464 95	Roof brush to be installed on middle roof plates (the roof layout must include a cut-out in the middle plate) Black
1	4 464 86	Plastic blind plate Plastic blind plate, depth 200 mm To be installed on right/left roof cut-outs to completely cover gaps
2	4 464 88	Roof inserts - cable guides Cable guide To be installed on right/left roof cut-outs to facilitate the management of top-of-cabinet cables
2	4 464 89	Cable guide end plate To be installed on right/left roof cut-outs to facilitate the management of top-of-cabinet cables
1	4 464 90	Cable guide set, 100 mm To be installed on right/left roof cut-outs to facilitate the management of top-of-cabinet cables
1	4 464 96	Roof middle cable guide, black To be installed on middle roof plates (the roof layout must include a cut-out in the middle plate)
1	4 464 68	Roof fan unit Roof fan unit - black Comprises 3 axial fans Flow with no load: 480 m ³ /h Flow under normal loads: over 300 m ³ /h To be connected using IEC-320 C13 connectors Can be combined using a cable with IEC-320 C13 / C14 connectors
4	4 464 98	Adjustable base legs Height 61 mm
2	4 464 97	Height 61 mm To be used with cabinets equipped with light duty casters
4	4 464 84	Castors Light duty casters Maximum dynamic load: 200 kg Black
1	4 464 85	Temperature management Thermostat, to be used to ensure the fan switches on at a selected temperature

Pack	Cat.Nos	Accessories for PDUs
		Frames
2	4 464 73	PDU brackets 1-fold
2	4 464 74	2-fold
		Cable trays
		Powdercoated PDU cable trays to be used for installing PDUs or for vertical cable management Width 170 mm: allows installation of up to three 1U PDUs, 2 intelligent PDUs or 1 High-Density PDU Cables can be attached to the tray using tie-wraps and/or Velcro
1	4 464 66	Black Height: 42U
1	4 464 67	Black Height: 47U