

Legrand cabling system LCS³ enclosures

wall-mounting cabinets



4 461 80




4 461 90



4 461 91



6 466 69

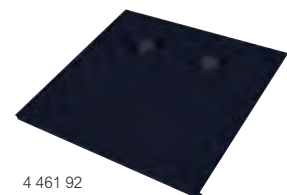

4 461 92



4 461 95

Pack	Cat.Nos	Wall-mounting cabinets with glass door			
		<p>Comprise:</p> <ul style="list-style-type: none"> - a wall element with integrated strain relief profile - 4 front and rear bars - 2 cable entry plates (top and bottom) - a set of two 19" profiles with adjustable depth (in stepsof 50 mm) and a pattern of holes on the side allowing accessories to be fitted. The casing consists of two identical upper and lower panels with ventilation slots at the rear, two identical side panels and a Securit glass door with an EK-333 lock and a handle - Possibility to adjust the cable holes' size on the spot thanks to the handy bend-away fingers <p>Width: 600 mm Colour: RAL 9011 Finish: powder coating Max. load: 100 kg Supplied with 1 rear plate, 4 depthwise bars, 2 cable entry plates, 2 x 19" profiles, 2 roof and floor plates, 2 side panels, 1 glass door, 1 assembly set, including assembly guide</p>			
		Capacity	Width (mm)	Depth (mm)	Height (mm)
1	4 461 80	6 U	600	525	342
1	4 461 81	9 U	600	525	476
1	4 461 82	9 U	600	625	476
1	4 461 83	12 U	600	525	609
1	4 461 84	12 U	600	625	609
1	4 461 85	15 U	600	525	742
1	4 461 86	15 U	600	625	742
1	4 461 87	21 U	600	625	1009

Pack	Cat.Nos	Accessories
1	4 461 90	<p>Cable entry strip for wall-mounting cabinet</p> <p>For dust-free cable entry. To be used in replacement of a top and/or bottom cable entry plate</p> <p>Supplied with 1 cable entry brush (360 mm), including fastenings</p>
1	4 461 91	<p>Corner guide set</p> <p>Comprises 2 corner guide supports (left and right) and fastening materials</p> <p>To be fitted specifically to the sides of the 19" profiles</p> <p>Supports heavy 19" equipment</p> <p>Suitable for a wall-mounting cabinet</p> <p>Material: galvanized sheet steel</p>
		<p>Roof plates with built-in fan unit</p> <p>Can be added as an option to generate a forced cooling air flow in the wall-mounting cabinet</p> <p>Replace an existing roof panel</p> <p>Can be used in conjunction with thermostat</p> <p>Cat.Nos 4 460 98</p> <p>Supplied with assembly materials</p>
1	4 461 92	Depth: 525 mm
1	4 461 93	Depth: 625 mm

accessories for wall-mounting cabinets

Pack	Cat.Nos	LCS ³ accessories
1	4 460 98	Thermostat
1	6 466 68	Horizontal cable ring
1	6 466 69	Vertical cable ring
		<p>19" profiles</p> <p>Can be used when equipment shelves need to be installed (with fixings at front and rear)</p> <p>Supplied in sets of 2</p>
1	4 461 95	Height: 6 U
1	4 461 96	Height: 9 U
1	4 461 97	Height: 12 U
1	4 461 98	Height: 15 U
1	4 461 99	Height: 21 U
		<p>Glass doors</p> <p>Width: 600 mm</p>
1	9 004 73	6 U glass door
1	9 004 74	9 U glass door
1	9 004 75	12 U glass door
1	9 004 76	15 U glass door
1	9 004 77	21 U glass door