

# Legrand cabling system LCS<sup>3</sup> enclosures

## 19" accessories



0 465 22



0 465 23



0 465 29



0 465 32



0 464 91



0 363 81

### Pack Cat.Nos 19" cable feedthrough panels

1	0 465 22	For organising and running patch cords Black RAL 9005 <b>Metal, 2 axes, Quick-Fix</b> Horizontal feedthrough passage. With cable rings plastic cable guide with controlled radius for optimum cord protection (compliance with the bending radius) Quick installation without screws 1 U	
1	0 465 23	2 U	
1	0 465 28	1 U	
1	0 465 29	2 U	
1	0 465 30	1 U	
1	0 465 31	2 U	

### 19" blanking plates


1	0 465 32	Black RAL 9005 <b>Plastic, direct clipping</b> 1 U	
1	0 465 33	2 U	
1	0 465 38	1 U	
1	0 465 39	2 U	
1	0 465 40	3 U	

### LED Lighting

1	0 464 91	Prewired with 2 m length power cord Magnets fastening With switch 60° swivel	
1	0 363 81	With presence sensor 120° swivel	

# Legrand cabling system LCS<sup>3</sup> enclosures

## cabling openrack and accessories

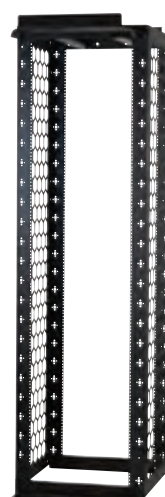

4 461 50



4 461 52



4 461 54



4 461 55



4 461 56



4 461 57



4 461 58



4 461 59

### Pack Cat.Nos Cabling openrack and accessories

1	4 461 50	Punched hole channel rack, 2130 mm x 609 mm (7 ft x 24"), black, square hole 9 mm (3/8")
1	4 461 52	Cable duct with door
6	4 461 54	Hexagonal cable feedthroughs
12	4 461 55	Bend limiting clips
4	4 461 56	Cable management spools
1	4 461 57	Cable management rings
1	4 461 58	Cable duct mounting brackets (top of rack Cablofil)
1	4 461 60	Overhead cable tray, 5 U, 19"
1	4 461 59	Horizontal cable management system
1	0 465 70	19" closed panel for cord management with pivoting cover - 1U - black - depth 172 mm
1	0 465 71	19" closed panel for cord management with pivoting cover - 2U - black - depth 172 mm
1	0 464 23	Set of 50 special screws for racks + 25 earthing claws