


## Legrand cabling system LCS<sup>3</sup> energy distribution - horizontal (1U/2U) PDUs (continued)

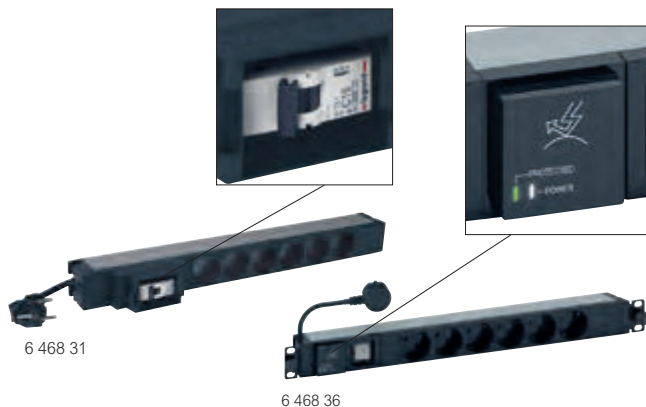

## Legrand cabling system LCS<sup>3</sup> energy distribution - PDUs to be equipped, accessories and DIN rails



To provide ~ electric power for IT equipment in enclosures  
 230 V - 50/60 Hz power supply  
 1U aluminium profile  
 End cap with metallic brackets and cable holder shape  
 Quick fixing (no screws) on 19" fixing centers  
 Can also be installed vertically by reverting the brackets (no screws)  
 2P+E outlets:  
 - C13 and C19 standard outlets are equipped with cord locking system to avoid any accidental disconnection. Universal solution compatible with all the cords (C14 plugs for C13 and C20 plugs for C19)  
 - French, German and British standard outlets are equipped with safety shutters  
 - French and German standard outlets are inclined at 55°  
 Black modules (outlets and functions)

Pack	Cat.Nos	19" Basic PDU with protection devices
		MCB and RCBO support with projecting edges to avoid accidental breakdown 3 m power supply cord with 16 A 2P+E French/German plug
1	6 468 31	<b>German standard</b> 6 outlets and a 16 A single pole Micro Circuit Breaker
1	6 468 32	9 outlets and a 16 A single pole Micro Circuit Breaker, 2 U height
		<b>French standard</b>
1	6 468 30	6 outlets and a 16 A single pole Micro Circuit Breaker
1	6 468 33	6 outlets and a 16 A 30 mA Residual-current Circuit Breaker
		<b>19" Basic PDU with surge protection</b>
		Protect against mains overvoltages while keeping outlets energised With light indicators: - one LED (white) gives information whether the PDU is supplied with power or not - one LED (green) indicates when surge protection module is efficient or must be replaced Equipped with hotswappable surge protection module Cat.No 6 468 97: even when the module is being replaced, the PDU and its outlets are still powered on 3 m power supply cord with 16 A 2P+E French/German plug
1	6 468 36	6 outlets - German standard - with switch
1	6 468 35	6 outlets - French standard - with switch
1	6 469 03	7 outlets - German standard

Pack	Cat.Nos	PDU to be equipped
1	6 468 99	Quick fixing (no screws) on 19" uprights Aluminium profile
1	6 468 98	19" PDU Capacity: 16 Mosaic modules 10" PDU Capacity: 8 Mosaic modules
		<b>PDU accessories</b>
		<b>Locking caps</b>
		To block the use of an outlet. A key is necessary to remove the cap and free the access Light grey RAL 7035
6	6 468 90	Set of 6 locking caps for French, Italian and German standard outlet + 1 key
6	6 468 92	Set of 6 locking caps for British standard outlet + 1 key
6	6 468 96	Set of 6 locking caps for Swiss standard T13 or T23 outlet + 1 key
6	6 468 94	Set of 6 locking caps for C13 outlet + 1 key
6	6 468 95	Set of 6 locking caps for C19 outlet + 1 key
		<b>Surge protection module</b>
1	6 468 97	To replace used module on PDU With light indicators: - 1 LED (white) to indicate voltage presence - 1 LED (green/red) to indicate the status of the surge protection module Hotswappable surge protection module: even when the module is being replaced, the PDU and its outlets are still powered on
		<b>Multi-application DIN rail</b>
		For mounting modular devices (circuit breakers, Legrand multimedia network components, etc) Capacity: 24 modules Height 4 U
1	0 465 46	Screw fixing on 19" uprights DIN profile rail with front panel Supplied with blanking plates 24 modules Black RAL 9005
1	0 465 47	Rear cover To be used for high current applications (greater than 50 V) To be associated with DIN profile rail Cat.No 0 465 46 Ensures IP XXB Supplied with terminal block (8 + 1 connections)