

Infinium™ HD

conversion adaptor panel and blank panels



Infinium™ HD

patch cords and trunks



HDFP-AME24LC




HDFP-AME48AC



HDFP-BLANK

Pack	Cat.Nos	Infinium acclAIM conversion adapter panels
1	HDFP-AME24LC	Provide a pass-through connection with LC duplex, LC quad, or MPO ports Adapter 24 fibers HDFP Adapter, 3 Adapters, OM4 HDFP Adapter, 3 Adapters, OM5 HDFP Adapter, 3 Adapters, OS2
1	HDFP-AME24QC	
1	HDFP-AME24AC	
1	HDFP-AME48LC	Adapter 48 fibers HDFP Adapter, 6 Adapters, OM4 HDFP Adapter, 6 Adapters, OM5 HDFP Adapter, 6 Adapters, OS2
1	HDFP-AME48QC	
1	HDFP-AME48AC	
1	HDFP-BLANK	Blank panel Black

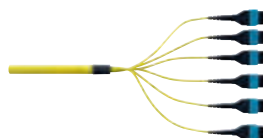

C76DEJMMY050M



C76DAEMMY010M

Pack	Cat.Nos	Patch cords
		Fiber patch cords are built to exceed industry standards for insertion and return loss Available in A-B polarity, per TIA 568 standard Available with Plenum, riser, low-smoke zero halogen (LSZH), rated jackets (or CPR – rated for EU use) Bend-insensitive fibre for optimal cable management TAA/BAA compliant TIA Channel compliant
		OS2 Length 1m - LC MDC Length 1m - MDC MDC Length 2m - MDC MDC Length 3m - MDC MDC Length 5m - MDC MDC
		OM4 Length 1m - LC MDC Length 1m - MDC MDC Length 2m - MDC MDC Length 3m - MDC MDC Length 5m - MDC MDC
		OM5 Length 1m - LC MDC Length 1m - MDC MDC
1	1 320 83	Infinium acclAIM trunks OS2 24 fibers, length 10m 24 fibers, length 20m 24 fibers, length 30m 24 fibers, length 40m 24 fibers, length 50m 48 fibers, length 50m OM4 24 fibers, length 10m 24 fibers, length 20m 24 fibers, length 30m 24 fibers, length 40m 24 fibers, length 50m 48 fibers, length 50m
1	1 320 88	
1	1 320 89	
1	1 320 90	
1	1 320 91	
1	1 320 81	
1	1 320 84	
1	1 320 85	
1	1 320 86	
1	1 320 87	
1	1 320 82	
1	1 320 92	



LCS³ fiber patch cords,
p. 1004



On-demand patch cords up to 50 m and trunks up to 150 m, **contact your local sale rep**