


DLPlus mini-trunking 60 x 20 and 75 x 20

profiles and finishing accessories

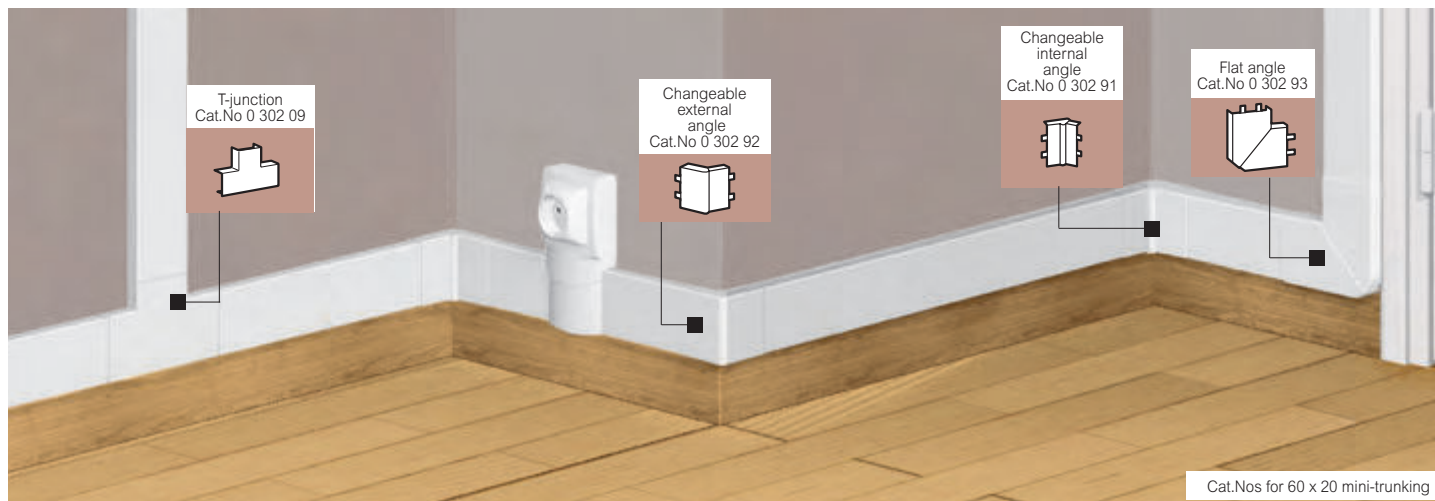

Selection chart **p. 1043**
 Wiring capacity chart **p. 1048**

| Pack | Cat.Nos | 3-compartment mini-trunking |
|-----------|---|--|
| 32' 20' | 60 x 20 0 301 14 75 x 20 0 300 33 | 3 compartments for distribution of high and low currents Length 2.10 m White |

| Pack | Cat.Nos | Finishing accessories |
|------|---|------------------------------|
| 10 | 60 x 20 0 302 90 75 x 20 0 303 00 | End cap |
| 10 | 0 302 91 0 303 01 | Changeable internal angle |
| 10 | 0 302 92 0 303 02 | Changeable external angle |
| 10 | 0 302 93 0 303 03 | Flat angle |
| 20 | 0 336 08 0 336 09 | Cover joint |
| 10 | 0 302 09 0 302 18 | Flat T-junction |
| 1 | 0 328 05 | Junction to floor duct |

| Pack | Cat.Nos | Special frames |
|---|----------|-----------------------|
| Supplied with end cap and divider for separation of currents | | |
| Installation alongside the mini-trunking For vertical or horizontal mounting of surface-mounting wiring accessories (p. 1049) | | |
| 10 | 0 314 08 | 1 gang |
| 5 | 0 314 18 | 2 gang |

1: Number of metres in pack

| Pack | Cat.Nos | Adaptors |
|--|----------|---|
| Adaptors for mounting Mosaic frames at the end of the mini-trunking | | |
| 10 | 0 316 45 | For 60 x 20 mini-trunking |
| 10 | 0 316 48 | For 75 x 20 mini-trunking (for 4 and 6 modules only) |
| Adaptors for mounting Mosaic frames alongside the mini-trunking | | |
| 10 | 0 317 07 | For Mosaic frames Cat.No 0 316 11 (p. 1047) |
| 5 | 0 317 08 | For Mosaic frames Cat.Nos 0 316 13 and 0 316 21 (p. 1047) |
| 5 | 0 317 09 | For Mosaic frames Cat.Nos 0 316 14 and 0 316 22 (p. 1047) |

Other frames for wiring accessories
(see opposite)

Surface-mounting wiring accessories **p. 1049**