


# DLPlus mini-trunking

## frames and installation accessories

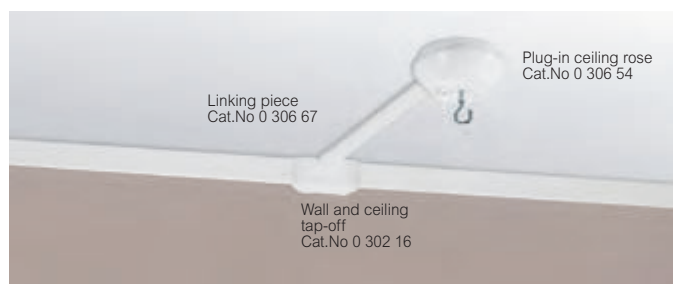

Pack	Cat.Nos	Mosaic frames
10	0 316 11	Supplied with support, plate and divider for separation of currents Vertical or horizontal mounting To be used with 2 module Mosaic sockets 2 modules
5	0 316 13	4 modules (for horizontal mounting only)
5	0 316 14	6 modules (for horizontal mounting only)
10	0 316 21	2 x 4 modules
10	0 316 22	3 x 4 modules

Pack	Cat.Nos	Junction boxes
10	0 303 16	White 75 x 75 x 35 mm
10	0 303 26	110 x 110 x 50 mm
10	0 303 36	150 x 150 x 65 mm

Pack	Cat.Nos	60 mm fixing centres wiring accessories frames
5	0 316 94	Installation alongside the mini-trunking Supplied with divider for separation of currents 1 gang, for vertical or horizontal mounting
5	0 316 95	2 gang, for horizontal mounting
5	0 316 96	3 gang, for horizontal mounting

Pack	Cat.Nos	Connection of luminaires
10	0 306 54	Plug-in ceiling rose unit supplied complete with connector hook and locking nut Maximum suspended weight: 25 kg as long as unit is equipped with a suitable fixing device
135	0 306 67	Linking piece between the above unit and the ring trunking Length 3 m
10	0 302 16	Wall and ceiling tap-off for 40 x 20 mini-trunking
10	0 302 26	Wall and ceiling tap-off for 60/75 x 20 mini-trunking
10	0 333 17	Wall and ceiling tap-off for 32 x 12.5 mini-trunking
10	0 333 29	Wall and ceiling tap-off for 32 x 16 mini-trunking

Pack	Cat.Nos	Cutting accessory for trunking
1	0 306 98	DLPlus cutting unit For cutting all plastic trunking Avoids vibration when cutting bases and covers Aluminium Dim.: 225 x 142 x 76 mm

Pack	Cat.Nos	Insulation accessory
10	0 304 18	Base joint Adjustable wall insulation joint, supplied in 5 m lengths Provides continuity between the trunking and the wall, in particular in internal angles

Pack	Cat.Nos	Fixing accessories for trunkings
		For fixing all plastic trunkings
		<b>Wall plugs for immediate fixing</b> No screws or nails required
100	0 308 98	For mini-trunking
100	0 308 99	For mini-trunking, skirting trunking and trunking
12	0 309 49	<b>Cartridge of Neoprene</b> Adhesive for glue gun
200	0 308 97	<b>DLP rapid wall plug</b> For 10 mm min. plasterboard walls at least 20 mm away from the concrete surface For fixing DLP plastic trunking in a single operation Used with a special tool for drill (Ø8 mm), supplied in each pack of 200 wall plugs Tensile resistance: 25 kg

Surface-mounting wiring accessories p. 1049

Mosaic wiring accessories p. 1172 to 1204