

## Surface-mounting wiring accessories


## Cable guide with adhesive



0 860 01

0 860 31

0 860 40

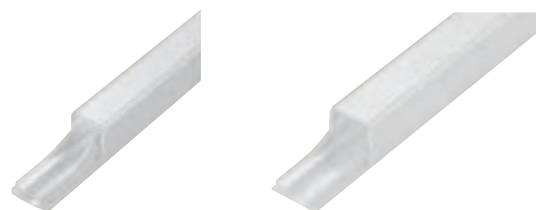

0 300 98

0 300 99

Pack	Cat.Nos	Switches
10	0 860 01	Two-way switch 10 AX - 250 V~
10	0 860 06	Push-button - NO - 6 A - 250 V~
<b>Socket outlets</b>		
10	0 860 31	2P+E socket outlet German standard 16 A - 250 V~ shuttered for child safety
10	0 860 29	2P+E socket outlet German standard 16 A - 250 V~
<b>TV socket</b>		
10	0 860 40	TV single socket - 0 - 2400 MHz

Pack	Cat.Nos	Cable guide with adhesive
132 <sup>1</sup>	0 300 98	<p>This cable guide is used to rapidly attach a cable to a wall without damaging it. It is equipped with a double base insulating the nail or the staple from the cable.</p> <p>2 mounting systems are provided:</p> <ul style="list-style-type: none"> <li>- nail or staple mounting</li> <li>- adhesive foam mounting: foam base equipped with a self-adhesive film (1 mm thick)</li> </ul> <p>The base is pre-drilled every 10 cm.</p> <p>Length: 2.10 m</p> <p>Supplied with cover</p> <p>Material: PVC</p> <p><b>For cable Ø3 to 6 mm</b></p> <ul style="list-style-type: none"> <li>○ White</li> <li>● Black</li> </ul>
132 <sup>1</sup>	6 010 18	
90 <sup>1</sup>	0 300 99	<p><b>For cable Ø7 and 9 mm</b></p> <ul style="list-style-type: none"> <li>○ White</li> <li>● Black</li> </ul>
90 <sup>1</sup>	6 010 17	
120 <sup>1</sup>	6 489 04	<p><b>16 x 16 mm</b></p> <ul style="list-style-type: none"> <li>○ White</li> </ul>

1: Number of metres in pack

When removing the frame, can be installed in DLPlus mini-trunking systems **p. 1042 to 1047**

DLP-S distribution mini-trunking with adhesive **p. 1050 to 1054**

20 x 12.5 mm and 32 x 16 mm cable guides with adhesive **p. 1044 and 1045**

Red catalogue numbers: New products