


Flexible cover snap-on DLP trunking 45 mm cover 50 x 180

routing sections and accessories

Cat.Nos for trunking 50 x 180

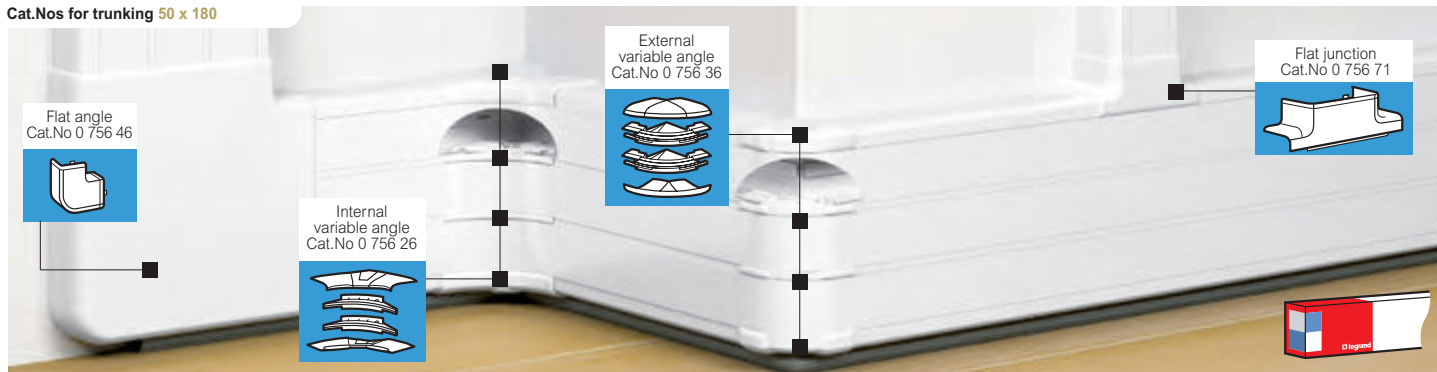

Example of installation:
One current type per compartment




Example of installation:
Wiring accessories in central compartment and distribution in side compartments



Selection chart p. 1054-1055
Wiring capacity chart p. 1066-1067

| Pack | Cat.Nos | Flexible cover snap-on trunking |
|-----------------|----------------------|--|
| | | 3-compartment trunking Snap-on trunking Can take any Mosaic or Arteor wiring accessory Includes: - 1 body with 3 compartments - 3 flexible covers, width 45 mm - Length 2 m - Length 2.5 m |
| 8 ¹ | 50 x 180 0 756 06 | |
| 5 ¹ | 0 110 24 | |
| | | Extra cover Width 45 mm Length 2 m |
| 20 ¹ | 0 756 08 | |
| | | Fishplate body joint Used to join 2 bodies and simplifies fixing sections to the wall - set of 2 |
| 10 | 0 756 61 | |
| | | Stick-on body joints For top part of body |
| 20 | 0 756 66 | |
| | | Cover joint Cover joint, width 45 mm |
| 10 ¹ | 0 756 69 | |
| | | Height spacer Length 2 m, colour charcoal grey For fitting 15 mm from the ground |
| 24 | 0 105 80 | |
| | | Soluclip accessory For installation with any Mosaic or Arteor function |
| 10 | 0 756 90 | |

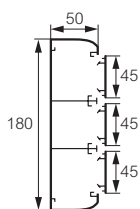

| Pack | Cat.Nos | Angles |
|------|----------------------|---|
| 5 | 50 x 180 0 756 26 | Internal angle, varies from 80° to 100° |
| 5 | 0 756 36 | External angle, varies from 85° to 120° |
| 5 | 0 756 46 | Flat angle at 90° |
| | | End cap Left or right end cap |
| 5 | 0 756 16 | |
| | | Flat junctions |
| | | With 80 mm wide sections Creates a junction with snap-on trunking 50 x 80 mm |
| 5 | 0 756 71 | |
| | | With 105 mm wide sections Creates a junction with snap-on trunking 50 x 105 mm |
| 5 | 0 756 75 | |
| | | Angled junction |
| 5 | 0 756 81 | Creates a junction in an internal angle with snap-on trunking 50 x 80 mm, 50 x 105 mm, 50 x 130 mm Must be used in conjunction with internal angle |
| | | Junction with floor duct |
| 5 | 0 756 88 | Creates a junction with a floor duct size 50 x 12 mm or 92 x 20 mm |

1: Number of metres in pack