


Flexible cover snap-on DLP trunking, grey - 45 mm cover 50 x 80 and 50 x 130

Cat.Nos for trunking 50 x 80



Cat.Nos for trunking 50 x 130

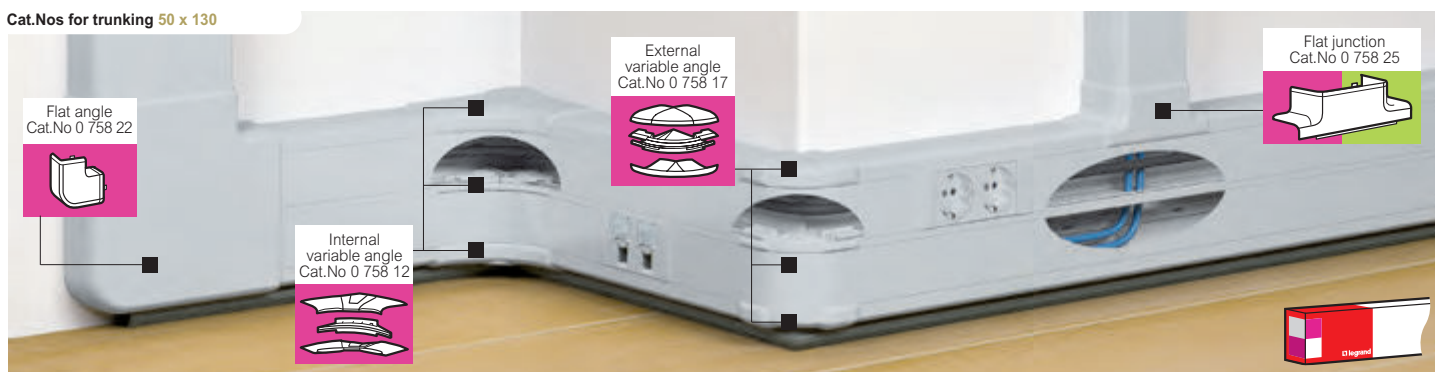

Selection chart p. 1054-1055
 Technical characteristics p. 1066-1067

Pack	Cat.Nos	Flexible cover snap-on trunking 50 x 80 and 50 x 130
20 ¹	50 x 80 0 758 00	1-compartment snap-on trunking Can take any Mosaic or Arteor wiring accessory Includes: - 1 body - 1 cover, width 45 mm Length 2 m
12 ¹	50 x 130 0 758 02	2-compartment snap-on trunking Can take any Mosaic or Arteor wiring accessory Includes: - 1 body with 2 compartments - 2 covers, width 45 mm Length 2 m
20 ¹	0 758 29	Extra cover Width 45 mm Length 2 m
26 ¹	50 x 80 0 756 09	Extra partition Divider for 50 x 80 trunking Length 2 m
10	0 758 30	Fishplate body joint Used to join 2 bodies and simplifies fixing sections to the wall - set of 2
20	0 758 33	Joint Stick-on body joint
10	0 758 35	Cover joint Cover joint, width 45 mm

1: Number of metres in pack

Pack	Cat.Nos	Angles	
10 5	50 x 80 0 758 10	0 758 12	Internal angle, varies from 80° to 120°
10 5	0 758 15	0 758 17	External angle, varies from 80° to 120°
10 5	0 758 20	0 758 22	Flat angle at 90°
10 5	50 x 80 0 758 05	50 x 130 0 758 07	End caps Left or right end cap
5	0 758 25		Flat junction Creates a junction with trunking 50 x 80 mm
10	0 758 36		Soluclip accessory For installation with any Mosaic or Arteor function