


Flexible cover snap-on DLP trunking, grey - 45 mm cover 50 x 180

Cat.Nos for trunking 50 x 180

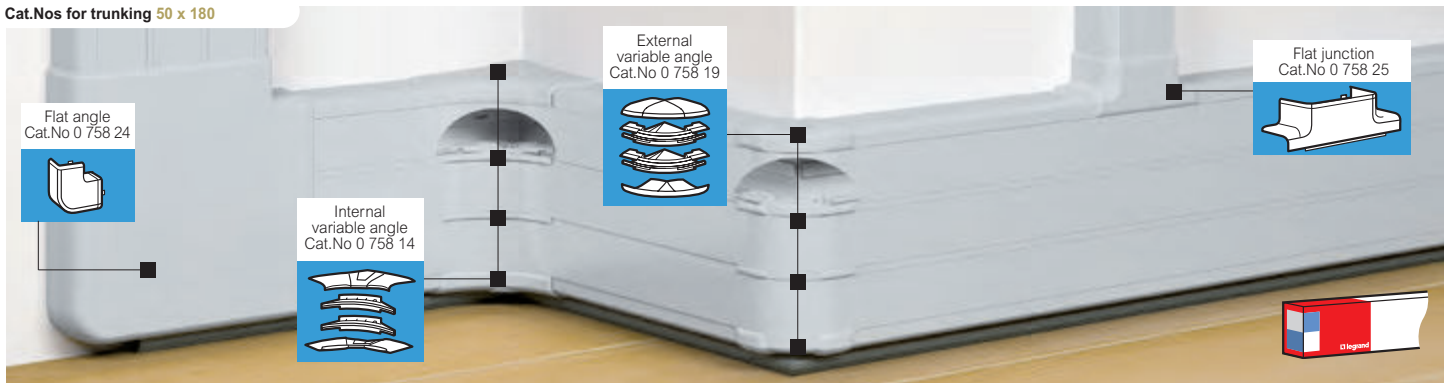

Selection chart p. 1054-1055
 Technical characteristics p. 1066-1067

Pack	Cat.Nos	Flexible cover snap-on trunking
8 ¹	50 x 180 0 758 04	3-compartment snap-on trunking Can take any Mosaic or Arteor wiring accessory Includes: - 1 body with 3 compartments - 3 covers, width 45 mm Length 2 m
20 ¹	0 758 29	Extra cover Width 45 mm Length 2 m
10	0 758 30	Fishplate body joint Used to join 2 bodies and simplifies fixing sections to the wall - set of 2
20	0 758 33	Joint Stick-on body joint
10	0 758 35	Cover joint Cover joint, width 45 mm

1: Number of metres in pack

Pack	Cat.Nos	Angles
5	50 x 180 0 758 14	Internal angle, varies from 80° to 120°
5	0 758 19	External angle, varies from 80° to 120°
5	0 758 24	Flat angle at 90°
5	0 758 09	End caps Left or right end cap
5	0 758 25	Flat junction Creates a junction with trunking 50 x 80 mm
10	0 758 36	Soluclip accessory For installation with any Mosaic or Arteor function

Sockets for snap-on DLP trunking, p. 1058