


Flexible cover universal DLP trunking 50 x 195 - 85 mm cover

White
length: 2 m


Flexible cover universal DLP trunking junctions and accessories

Cat.Nos for 50 x 195 trunking

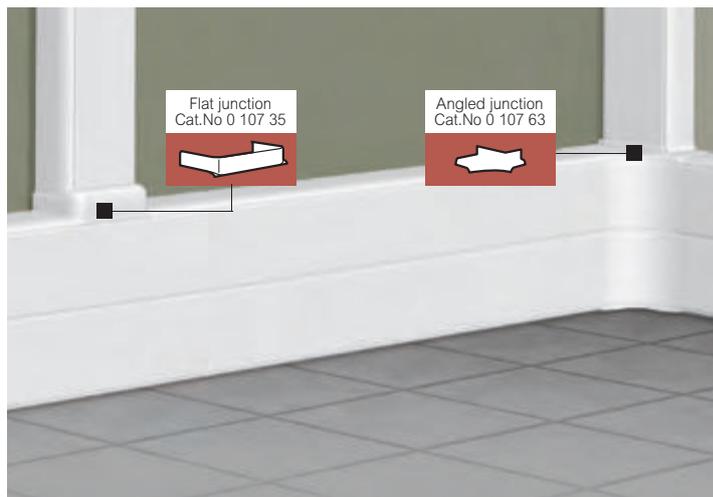

Selection chart p. 1068-1069
 Wiring capacity chart p. 1074-1075

Selection chart p. 1068-1069

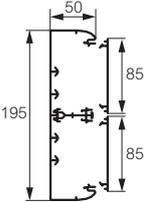Pack	Cat.Nos	Flexible cover universal trunking 50 x 195
8'	0 104 70	Trunking with partition Supplied with: - one 50 x 195 mm body - two flexible 85 mm width covers Fits onto the whole trunking including in internal and external angles Installation: can be used with Mosaic/Arteor ranges or DIN rail equipment Length 2 m 
24'	0 105 82	Partition  Separation partition Length 2 m
20	0 106 91	Joints  Body joint For aligning bases during installation
20	0 106 92	 Body joint, attached with adhesive (fit at the end of installation)
10	0 108 02	 Cover joint
Angles flexible cover for universal trunking 50 x 105		
Internal and external bends Include the 3 components making the angle (parts for the top and bottom and the partition junction) on which the flexible cover is fitted		
5	0 106 06	 Changeable internal bend, from 85° to 95° for 50 x 150 and 50 x 195 mm trunkings
5	0 106 35	 Changeable external bend, from 60° to 120° for 50 x 150 and 50 x 195 mm trunkings
2	0 107 92	Flat angle  90° flat angle
5	0 107 11	End cap for flexible cover universal trunking 50 x 195  Left or right end cap

1: Number of metres in pack

Pack	Cat.Nos	Junctions
5	0 107 35	Flat junctions  For tap-off to a 80 mm wide profile
5	0 107 39	 For tap-off to a 80 mm wide profile
5	0 107 37	 For tap-off to a 105 mm wide profile equipped with a 65 mm cover
5	0 107 36	 For tap-off to a 105 mm wide profile equipped with a 85 mm cover
5	0 107 40	 For tap-off to a 150 mm wide profile
Angled junction For tap-off in an internal angle to 35 x 105, 50 x 80, 50 x 105		
5	0 107 63	 For use with internal angle Cat.No 0 106 06 (p. 1071)
5	0 107 65	 For use with internal angle Cat.No 0 106 02 (p. 1070)
Accessories		
50	0 106 82	 Clip for 40, 65 and 85 mm covers
50	0 106 81	 Clip for 65 mm covers
100	0 308 81	 Base for clamp