

# Rigid cover DLP-S snap-on trunking 85 x 50 and 100 x 50

45 mm cover

## Cat.Nos for trunking 85 x 50




## Cat.Nos for trunking 100 x 50



Selection chart p. 1080-1081  
 Technical characteristics p. 1088

| Pack | Cat.Nos                        | <b>Rigid cover snap-on trunking</b>                                                                                                                                                  | Pack    | Cat.Nos                                    | <b>Angles</b>                                                                                                   |
|------|--------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------|--------------------------------------------|-----------------------------------------------------------------------------------------------------------------|
| 20'  | 85 x 50<br>6 380 20   100 x 50 | <b>1-compartment trunking</b><br>Includes:<br>- 1 body<br>- 1 cover width 45 mm<br>Can take 45 mm wiring accessories, such as Arteor or Mosaic<br>Supplied in 10 units of 2 m length | 16   20 | 85 x 50<br>6 380 27   100 x 50<br>6 380 17 | <b>Fixed angles at 90°</b>                                                                                      |
|      |                                |                                                                                                                                                                                      | 16   20 | 6 380 28   6 380 18                        | Internal angle                                                                                                  |
|      |                                |                                                                                                                                                                                      | 8   16  | 6 380 29   6 380 19                        | External angle                                                                                                  |
| 16'  | 6 380 30                       | Supplied in 8 units of 2 m length                                                                                                                                                    |         |                                            | Flat angle                                                                                                      |
| 32   | 6 380 08                       | <b>Partition</b><br>Separation partition<br>Length 2 m                                                                                                                               | 10      | 85 x 50<br>6 380 25   100 x 50<br>6 380 35 | <b>End cap</b><br>End cap                                                                                       |
| 10   | 6 380 26   6 380 36            | <b>Body joint</b><br>For aligning trunking body during installation                                                                                                                  | 5       | 85 x 50<br>6 380 24   100 x 50<br>6 380 34 | <b>Flat junction</b><br>Creates a junction between 85 x 50 mm vertical trunking and any other size of the range |
| 10   | 6 380 00                       | <b>Cover joint</b><br>Cover joint width 45 mm                                                                                                                                        |         |                                            |                                                                                                                 |

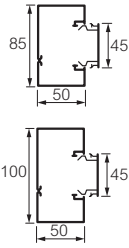

1: Number of meters in pack