

Rigid cover DLP-S universal trunking 100 x 50


75 mm cover

Cat.Nos for trunking 100 x 50



Selection chart p. 1084-1085
 Technical characteristics p. 1088

Pack	Cat.Nos	Rigid cover universal trunking
16 ¹	100 x 50 6 380 38	1-compartment trunking Includes: - 1 body - 1 cover width 75 mm Supplied in 6 units of 2 m length Can take : - 45 mm wiring accessories (Arteor or Mosaic) with 75 mm cover support frames (p. 1087) - British standard wiring devices (Eloé, Galion, Belanko S, Mallia Senses, Synergy) with universal support Cat.No 6 380 05 (p. 1087)
32 ¹	6 380 08	Partition Separation partition Length 2 m
10	6 380 36	Body joint For aligning trunking body during installation
50	6 380 01	Cover joint Cover joint for 75 mm cover
Angles		
20	100 x 50 6 380 11	Fixed angles at 90° Internal angle
20	6 380 12	External angle at 90°
16	6 380 13	Flat angle at 90°

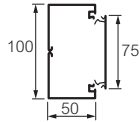

Pack	Cat.Nos	End cap
10	100 x 50 6 380 35	End cap
5	100 x 50 6 380 34	Flat junction Creates a junction between 100 x 50 mm vertical trunking and any other size of the range

1: Number of meters in pack