

Rigid cover DLP-S universal trunking 190 x 50


75 mm cover

Cat.Nos for trunking 190 x 50



Selection chart p. 1084-1085
 Technical characteristics p. 1088

Pack	Cat.Nos	Rigid cover universal trunking
8'	190 x 50 6 380 50	2-compartment trunking Includes: - 1 body - 2 covers width 75 mm Supplied in 4 units of 2 m length Can take : - 45 mm wiring accessories (Arteor or Mosaic) with 75 mm cover support frames (p. 1087) - British standard wiring devices (Eloé, Galion, Belanko S, Mallia Senses, Synergy) with universal support Cat.No 6 380 05 (p.1087)
32'	6 380 08	Partition Separation partition Length 2 m
10	6 380 56	Body joint For aligning trunking body during installation
50	6 380 01	Cover joint Cover joint for 75 mm cover
10	190 x 50 6 380 51	Angles Internal angle from 80° to 120°
10	6 380 52	External angle from 60° to 120°
5	6 380 53	Flat angle at 90°
10	190 x 50 6 380 55	End cap End cap
5	190 x 50 6 380 54	Flat junction Creates a junction between 100 x 50 mm vertical trunking and any other size of the range

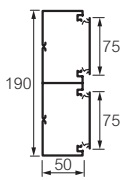

Pack	Cat.Nos	Supports for 45 mm wiring devices
10	6 380 71	For mounting Arteor wiring accessories Clip-on supports, which can be fitted side by side Supplied with white finishing plate For cover 75 mm width For 2 modules
5	6 380 72	For 4 modules
5	6 380 73	For 6 modules
10	6 380 05	Universal support British standard wiring devices such as Belanko S, Mallia Senses or Synergy ranges For cover 75 mm width
5	6 117 88	For 60 mm fixing centres wiring devices such as Niloé, Kaptika or Mosaic ranges (equipped with support frame and plate) For cover 75 mm width

1: Number of meters in pack