


Snap-on DLP aluminium trunking system 50 x 85 and 50 x 130 mm

Cat.Nos for 50 x 130 mm trunking

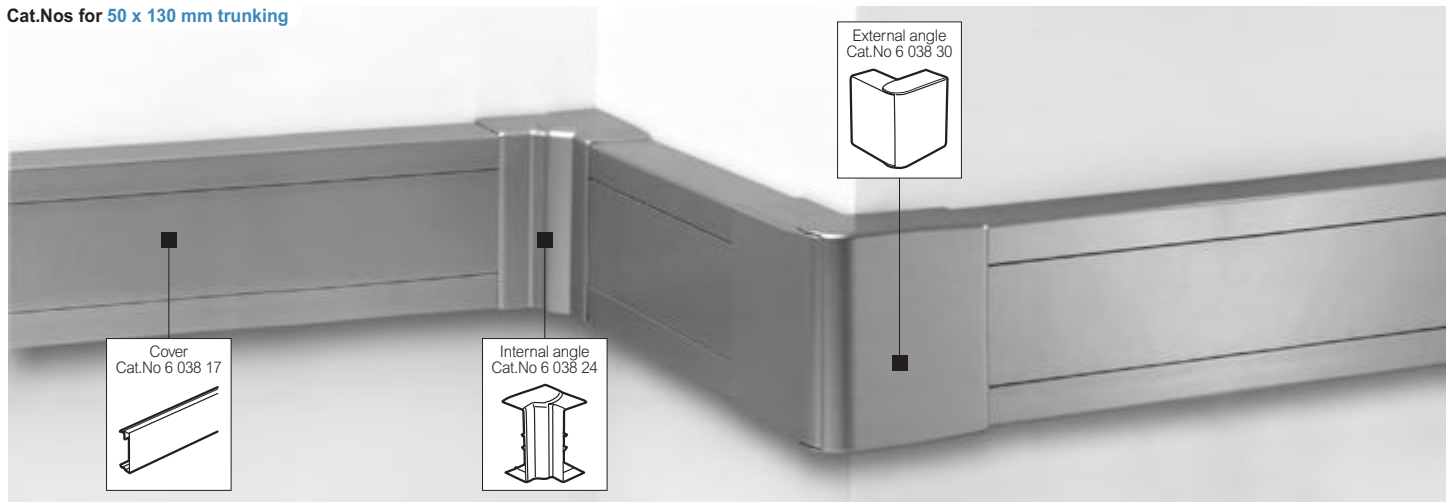

Selection chart p. 1089

Pack	Cat.Nos	Snap-on trunking	Angles
24'	50 x 85 6 038 11	1-compartment trunking Snap-on aluminium trunking Can take any Mosaic or Arteor wiring accessory Supplied without cover Length 2 m 2-compartment trunking Snap-on aluminium trunking Can take any Mosaic or Arteor wiring accessory Supplied without cover Length 2 m	10 18 50 x 85 6 038 22 50 x 130 6 038 24 10 18 6 038 28 6 038 30 10 14 6 038 34 6 038 36
12'	6 038 13		Internal angle, varies from 80° to 120° External angle, varies from 80° to 120° Flat angle for 50 x 85 mm trunking, at 90°
24'	6 038 17	Cover Width 45 mm, Length 2 m	End caps Left or right end cap
32'	6 373 58	Partitions Length 2 m PVC separation partition Aluminium separation partition	Cabling accessory Earth link
32'	6 038 47		
10	6 038 19	Cover joint Cover joint PVC Alu finish, width 45 mm	
5	6 038 59	Coupling pin Coupling pin used to join 2 bodies	
10	6 038 57 6 038 58	Fixing clip For 45 mm wiring devices like Mosaic and Arteor With anti-pullout and anti-slip system for perfect fitting of the mechanisms on DLP-S and DLP aluminium snap-on trunking and snap-on columns and mini-columns White finish Aluminium finish	
10			

1: Number of metres in pack