


# Aluminium universal DLP trunking system

## 50 x 150 / 65 x 150 and 50 x 195

Cat.Nos for 50 x 195 trunking

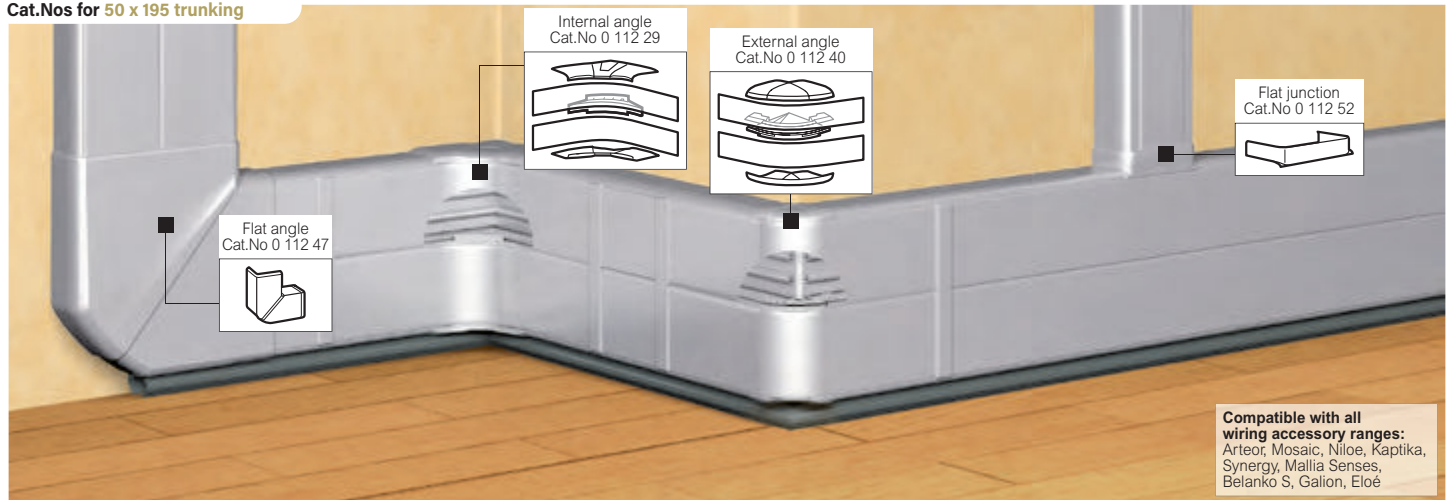

Selection chart p. 1091  
Technical characteristics p. 1095

Pack	Cat.Nos	Bodies		Pack	Cat.Nos	Bodies	
4 <sup>1</sup>	50 x 150 0 111 02   65 x 150 0 111 03	Supplied without cover Allow fitting of partial covers length 2 m		4 <sup>1</sup>	50 x 195 0 111 04	Supplied without cover Allow fitting of partial covers length 2 m	
16 <sup>1</sup> 8 <sup>1</sup>	0 111 10 0 111 12	Partial rigid cover 65 mm width Full rigid cover 130 mm width		16 <sup>1</sup>	0 111 11	Partial rigid cover 85 mm width	
12 <sup>1</sup>	50 x 150 0 111 06   65 x 150 0 111 07	Division partition for cover 65 mm width		24 <sup>1</sup>	50 x 195 0 111 08	Separation partition	
24 <sup>1</sup>	0 111 08   0 111 09	Separation partition		12 <sup>1</sup>	0 111 06	Division partition for cover 85 mm width	
10	50 x 150 0 111 60   65 x 150 0 111 89	End cap		10   5	50 x 195 0 111 61	End cap	
5   2	0 112 45   0 112 46	Flat angle		2	0 112 47	Flat angle	
1	0 112 38   0 112 39	External angle		1	0 112 40	External angle	
1	0 112 27   0 112 28	Internal angle		1	0 112 29	Internal angle	
5	0 112 52   0 112 54	Flat junction 50 x 105 trunking, cover width 65 mm		5	0 112 52	Flat junction 50 x 105 trunking, cover width 65 mm	
5	0 112 51   0 112 53	Flat junction 50 x 105 trunking, cover width 85 mm		5	0 112 51	Flat junction 50 x 105 trunking, cover width 85 mm	
20	0 111 66	Body joint attached with adhesive (fit at the end of installation)		20	0 111 66	Body joint attached with adhesive (fit at the end of installation)	
20	0 111 92	For aligning bases during installation		20	0 111 92	For aligning bases during installation	
10	0 111 62	Cover joint for 65 mm cover		10	0 111 63	Cover joint for 85 mm cover	

1: Number of metres in pack