


Incara™ Disq 80 Qi

for offices and collaborative spaces

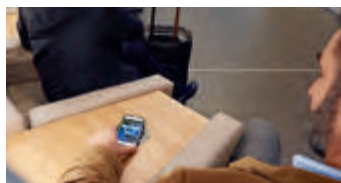

0 776 40L supplied with sticker



Technical characteristics p. 1102

Wireless charger for fast charging a smartphone with a Qi receiver
 Standby power consumption < 0.07W
 Energy efficiency > 85%
 Conforms to the WPC (Wireless Power Consortium) Qi standard
 Conforms to standard EN 62479 (EMF emissions)
 Conforms to ICNIRP specifications (health protection)
 Does not interfere with other wireless signals (Zigbee, DTT, GSM, 4G, etc.)

Pack	Cat.Nos	Ready to install wireless charger
		<p>Specially designed for mounting horizontally on furniture in passageways or transit areas, offices or kitchen surfaces, etc. IP 44 - IK08 - Class II SELV Equipped with an 8 cm² induction antenna for fast smartphone charging 80 mm diameter cut-out using hole saw Cat.No 0 885 08, inlaid diameter 85 mm, extra-slim with thickness < 1.5 mm Charger locks under furniture with a butterfly nut WPC Qi certified Aluminium colour</p>
1	0 776 40L	<p>Complete kit with 1 charger for furniture Ø80 (plug) 1 x 15 W charger with 1 x 25 W power supply Power supply equipped with a 2.5 m cord 2P European plug (also available with plug conforming to US, BS, Australia or China standards; please consult us) Supplied with the following accessories: - 2.5 m RJ 45 cable - Adhesive bases and cable ties for attaching cables - Sticker Ø85-110 for identification purposes in public areas</p>
1	0 776 45L	<p>Complete kit with 4 chargers for furniture Ø80 (cable) 4 x 15 W chargers with 1 x 100 W power supply Power supply 2 x 2.5 mm² for cable connection Provides several power supplies on a single line Supplied with 4 x 1 m RJ 45 cables and associated accessories Charger wired in star or series connection Plug & Play</p>
1	0 776 46L	<p>Complete kit with 4 chargers for furniture Ø80 (plug) 4 x 15 W chargers with 1 x 100 W power supply Power supply equipped with a 2.5 m cord 2P European plug (also available with plug conforming to US, BS, Australia or China standards; please consult us) Supplied with 4 x 1 m RJ 45 cables and associated accessories Charger wired in star or series connection Plug & Play</p>

Pack	Cat.Nos	Chargers for customer assembly
		<p>15 W wireless chargers (IP 44, IK08) Single unit with power supply Cat.No 0 776 38L Multiple units with power supply/supplies Cat.No 0 776 39L Option to print a custom logo</p>
1	0 776 42L	○ White
1	0 776 43L	● Black
1	0 776 41L	● Aluminium
		<p>Movable power supplies for wireless chargers</p>
1	0 776 38L	25 W power supply with 2P plug and RJ 45 cable
1	0 776 39L	100 W power supply, 2 x 2.5 mm ² , tap-off possible Supplied with 4 x 1 m RJ 45 cables Charger wired in star or series connection Plug & Play