


Incara™ Top Access

for offices and meeting rooms



Incara™ Tower 60 and 120 - German standard - for meeting rooms and kitchen areas

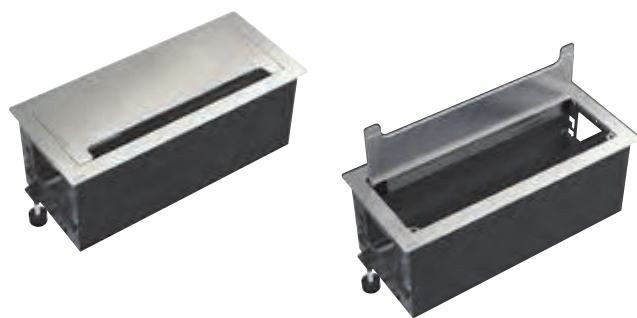

6 548 70 with cover closed and cover open



6 549 74

6 549 82

6 549 83

Technical characteristics p. 1110

For flush-mounting in furniture, compatible table thickness 10 to 40 mm
Metal
Easy storage for an office module, multi-outlet or surplus cable in the workspace
Features a dedicated fixing system for Legrand office modules

Pack	Cat.Nos	Incara Top Access
1	6 548 70	295 mm size
1	6 548 71	● Metal
1	6 548 72	○ White
		● Black
1	6 548 73	385 mm size
1	6 548 74	● Metal
1	6 548 75	○ White
		● Black

Technical characteristics p. 1110

For flush-mounting in furniture (meeting tables)
Max. power: 3680 W at 230 V~
2P+E sockets: 16 A 250 V~ 50/60 Hz, equipped with safety shutters, conforming to standard IEC 60884-1
USB chargers: 220-250 V~ power supply, conforming to standard IEC 62368-1

Pack	Cat.Nos	Incara Tower 60
		Ø60 mm cut-out Metal finish Manual opening With 2 m cord and 2P+E plug Compatible table thickness: 6-50 mm
1	6 549 76	Power connections Composition: - 4 x 2P+E sockets
1	6 549 74	Composition: - 3 x 2P+E sockets - 1 x 15 W USB Type-A + Type-C charger
1	6 549 75	Power and data connections Composition: - 3 x 2P+E sockets - 2 x RJ 45 cat. 6 UTP sockets - 1 x 15 W USB Type-A + Type-C charger
1	6 549 77	Composition: - 4 x 2P+E sockets - 2 x RJ 45 cat. 6 UTP sockets

Pack	Cat.Nos	Incara Tower 120
		Ø121 mm cut-out Black/metal finish Automatic opening Functions distributed on all 4 sides Ideal for round tables With 2 m cord and 2P+E plug Compatible table thickness: 6-80 mm
1	6 549 82	Power connections Composition: - 4 x 2P+E sockets - 2 x 15 W USB Type-A + Type-C chargers
1	6 549 83	Power connections with wireless charger Composition: - 4 x 2P+E sockets - 2 x 15 W USB Type-A + Type-C chargers - 1 wireless charger (glass, with LED to indicate charger status)

Multi-outlet extensions p. 835