


Incara™ Pop-up - British standard

for offices and meeting rooms

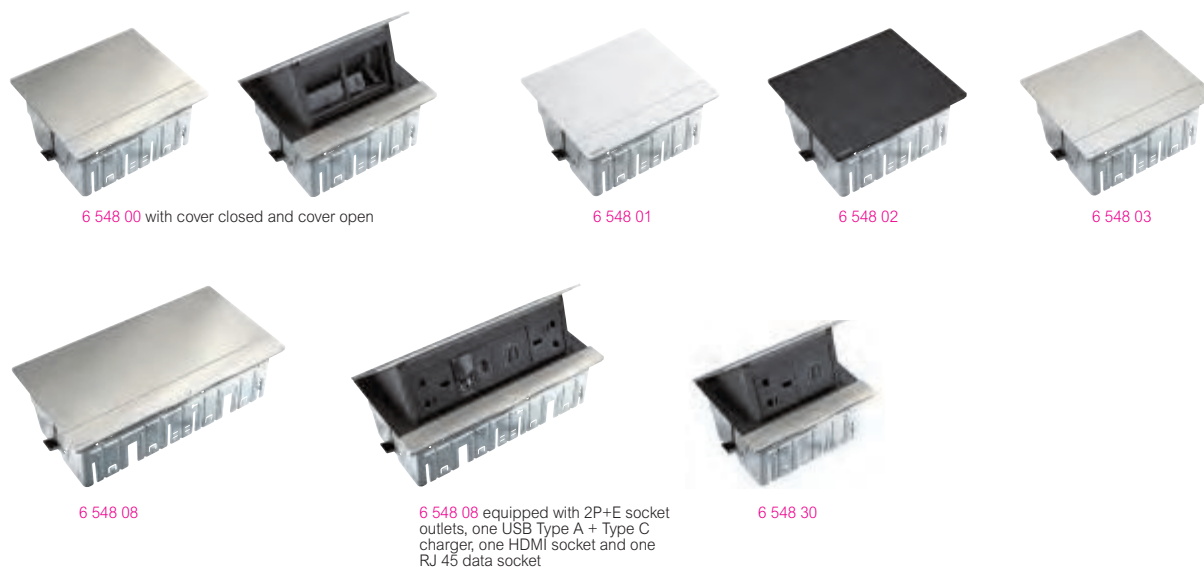

Technical characteristics p. 1119

For flush-mounting in furniture, compatible desktop thickness 15 to 40 mm
Metal. Protective film
Conform to standard BS 5733

Pack	Cat.Nos	Incara Pop-up to be equipped
		To be equipped with Mosaic functions
		4 modules
1	6 548 00	● Brushed Aluminium
1	6 548 01	○ White
1	6 548 02	● Black
1	6 548 03	● Aluminium
1	6 548 12	● Brushed Aluminium (IP 44)
1	6 548 14	● Brushed Aluminium with wireless charger Blue LED to indicate product is operating correctly
		2 x 4 modules
1	6 548 04	● Brushed Aluminium
1	6 548 05	○ White
1	6 548 06	● Black
1	6 548 07	● Aluminium
		8 modules
1	6 548 08	● Brushed Aluminium
1	6 548 09	○ White
1	6 548 10	● Black
1	6 548 11	● Aluminium

Pack	Cat.Nos	Incara Pop-up pre-equipped
		2P+E sockets 250 VA equipped with 5 A fuse and safety shutters, conforming to standard BS 1363-2 USB chargers: 110/240 V~ 50/60 Hz power supply, conforming to standard IEC 62368-1 ● Brushed Aluminium
		4 modules with 2 x 2P+E sockets 2 m cord and 2P+E plug
1	6 548 33	With 2 m cord and 2P+E plug
1	6 548 34	With 2 m cord and GST18i3 Wieland connector
		4 modules with 1 x 2P+E socket + 1 x 15 W USB Type-A + Type-C charger
1	6 548 30	With 2 m cord and 2P+E plug
1	6 548 31	With 2 m cord and GST18i3 Wieland connector
		4 modules with 1 x 2P+E socket + 1 x USB Type-C 30 W Power Delivery charger
1	6 548 39	With 2 m cord and 2P+E plug
		2 x 4 modules
		Composition: 2 x 2P+E sockets + 2 x 15 W USB Type-A + Type-C charger
1	6 548 36	With 2 m cord and 2P+E plug
1	6 548 37	With 2 m cord and GST18i3 Wieland connector

Other configurations, socket standards and finishes available on request or via the pCon software