

Incara™ Flip-up - British standard

for meeting rooms



Incara™ Top Access

for offices and meeting rooms




6 549 58 with cover closed and cover open

Technical characteristics p. 1121

For flush-mounting in furniture, compatible table thickness 15 to 40 mm
 Ready to use
 Max. power: 3680 W at 230 V~
 Conform to standard BS 5733
 2P+E sockets: 250 V~ 50/60 Hz, equipped with 5 A fuse and safety shutters, conforming to standard BS 1363-2
 USB chargers: 110-240 V~ 50/60 Hz power supply, conforming to standard IEC 62368-1
 Feedthrough RJ 45 and HDMI sockets
 Snap-on fixing via retractable clamps

Pack	Cat.Nos	Incara Flip-up multi-outlets for flush-mounting
		8 power modules Composition: - 2 x 2P+E sockets - 1 x 15 W USB Type-A + Type-C charger ● Metal finish With 2 m cord and 2P+E plug With 0.5 m cord and GST18i3 Wieland connector
1	6 549 58	
1	6 549 60	
		8 power and data modules Composition: - 1 x 2P+E sockets - 2 x RJ 45 cat. 6 UTP feedthrough socket, 1 module - 1 x feedthrough HDMI socket - 1 x 15 W USB Type-A + Type-C charger ● Metal finish With 2 m cord and 2P+E plug With 0.5 m cord and GST18i3 Wieland connector
1	6 549 59	
1	6 549 61	
		12 power modules Composition: - 3 x 2P+E flush sockets - 1 x 15 W USB Type-A + Type-C charger ● Metal finish With 2 m cord and 2P+E plug With 0.5 m cord and GST18i3 Wieland connector
1	6 549 64	
1	6 549 66	
		12 power and data modules Composition: - 2 x 2P+E sockets - 3 x RJ 45 cat. 6 UTP feedthrough sockets, 1 module - 1 x feedthrough HDMI socket - 1 x 15 W USB Type-A + Type-C charger ● Metal finish With 2 m cord and 2P+E plug With 2 m cord and GST18i3 Wieland connector
1	6 549 65	
1	6 548 67	

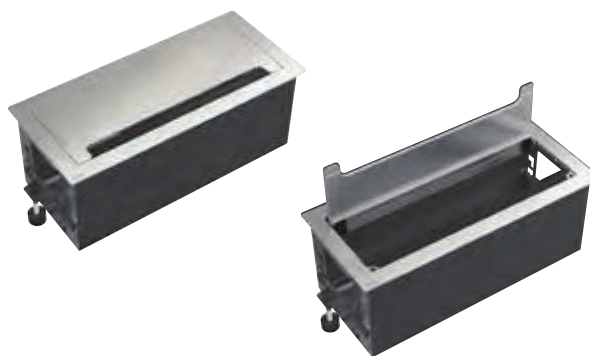

6 548 70 with cover closed and cover open

Technical characteristics p. 1122

For flush-mounting in furniture, compatible table thickness 10 to 40 mm
 Metal
 Easy storage for an office module, multi-outlet or surplus cable in the workspace
 Features a dedicated fixing system for Legrand office modules

Pack	Cat.Nos	Incara Top Access
		295 mm size ● Metal ○ White ● Black
1	6 548 70	
1	6 548 71	
1	6 548 72	
		385 mm size ● Metal ○ White ● Black
1	6 548 73	
1	6 548 74	
1	6 548 75	

Other configurations, socket standards and finishes available on request or via the pCon software