



Universal mini-columns

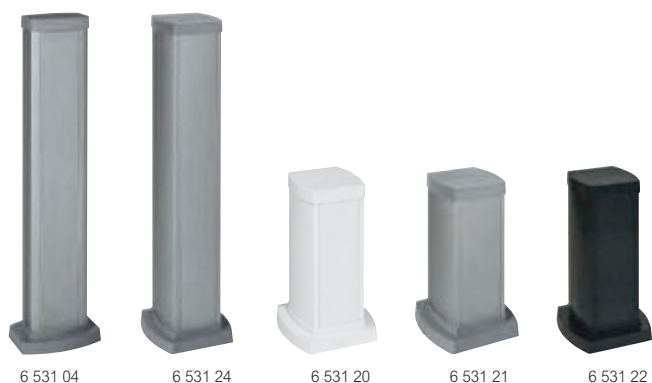

For distribution of power vertically (with the input in separate ducts for high voltage and low voltage cables)
Power supply via the floor or the ceiling (with ovaline kits)
To be equipped with supports for wiring accessories
Cover width 80 mm

Pack	Cat.Nos	1 compartment
		Aluminium body and covers
		White finish
1	6 531 00	Height 0.30 m
1	6 531 03	Height 0.68 m
		Aluminium finish
1	6 531 01	Height 0.30 m
1	6 531 04	Height 0.68 m
		Black finish
1	6 531 02	Height 0.30 m
1	6 531 05	Height 0.68 m
		2 compartments
		Aluminium body and covers
		White finish
1	6 531 20	Height 0.30 m
1	6 531 23	Height 0.68 m
		Aluminium finish
1	6 531 21	Height 0.30 m
1	6 531 24	Height 0.68 m
		Black finish
1	6 531 22	Height 0.30 m
1	6 531 25	Height 0.68 m
		Ovaline kits
		For 1 compartment cover width 80 or 2 compartment cover width 45 mini-columns For powering the mini-column via the ceiling
1	6 530 63	White finish
1	6 530 64	Aluminium finish
1	6 530 65	Black finish
		Accessories for 1 compartment mini-columns
1	6 530 84	Table - white finish
1	6 530 86	Movable foot - white finish
1	6 530 87	Movable foot - aluminium finish
1	6 530 89	Movable foot - black finish
1	6 530 88	Set of 4 wheels with cable-holder

Universal columns

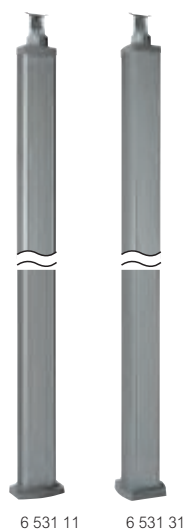

For distribution of power vertically (with the input in separate ducts for high voltage and low voltage cables)
Power supply via the floor or the ceiling (with ovaline kits)
To be equipped with supports for wiring accessories
Cover width 80 mm

Pack	Cat.Nos	1 compartment		
		Aluminium body and covers		
		White finish		
		Column body height (m) Total height between the floor and the ceiling (m) Min. Max.		
1	6 531 10 ¹	2.67	2.77	4.05
1	6 531 13 ¹	3.92	4.02	5.30
		Aluminium finish		
1	6 531 11 ¹	2.67	2.77	4.05
1	6 531 14 ¹	3.92	4.02	5.30
		Black finish		
1	6 531 12 ¹	2.67	2.77	4.05
1	6 531 15 ¹	3.92	4.02	5.30
		2 compartments		
		Aluminium body and covers		
		White finish		
		Column body height (m) Total height between the floor and the ceiling (m) Min. Max.		
1	6 531 30 ¹	2.67	2.77	4.05
1	6 531 33 ¹	3.92	4.02	5.30
		Aluminium finish		
1	6 531 31 ¹	2.67	2.77	4.05
1	6 531 34 ¹	3.92	4.02	5.30
		Black finish		
1	6 531 32 ¹	2.67	2.77	4.05
1	6 531 35 ¹	3.92	4.02	5.30

¹ For installation with false ceiling, please consult the technical sheet and installation instructions