

Accessories, boxes and supports for universal columns



6 531 79

Pack	Cat.Nos	Accessories
1	6 531 69	Metal separation partition, length 1.1 m
1	6 531 80	Panel indicator 150 x 150 mm
1	6 531 83	Shelf, white finish

Pack	Cat.Nos	Boxes
1	5 102 01	1-gang mounting box
1	5 102 02	2-gang mounting box
1	5 102 03	Junction box

Pack	Cat.Nos	Supports for wiring accessories
1	6 531 79	Support for mounting Arteor, Mosaic and Belanko S wiring accessories
1	6 531 78	Support adaptor for Mosaic wiring accessories 2 and 3 modules


Pack	Cat.Nos	Supports for rail equipment (columns and mini-columns)
<p>For mounting rail equipment (such as MCBs) on columns and mini-columns. To be used with two 0.5-module spacing units Cat.No 4 063 07 (p. 75) Capacity: 1 module Equipped with protective cover to prevent unwanted triggering For installation on universal columns and mini-columns use a fixing support Cat.No 6 531 79, a 4-module Mosaic support plate Cat.No 0 802 52 (p. 1204) and a 4-module Mosaic plate Cat.Nos 2 778 14L, 0 793 14L or 0 790 54L (p. 1202)</p>		
5	0 310 69	White finish
5	0 307 87	Aluminium finish
5	6 530 75	Black finish




Universal mini-columns and columns

Dimensions (in mm)

1-compartment columns and mini-columns

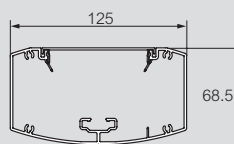

2-compartment columns and mini-columns

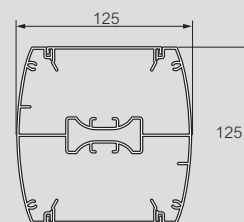

Wiring capacity

1-compartment columns

	1-compartment	1-compartment (with 1 mechanism)
Max. capacity of conductors (for each type of conductor)		
Compartment	A	A
Total cross-section (mm ²)	6900	5050
Number of cables	Ø7 mm	84
	Ø9 mm	52
	Ø11 mm	32

2-compartment columns

	2-compartment		2-compartment (with 1 mechanism)	
Max. capacity of conductors (for each type of conductor)				
Compartment	A	B	A	B
Total cross-section (mm ²)	6170	6170	4280	6170
Number of cables	Ø7 mm	106	72	106
	Ø9 mm	62	42	62
	Ø11 mm	44	26	44

Installation principle for special support for mounting rail equipment Cat.Nos 0 307 87, 0 310 69 and 6 530 75

