

Over floor trunking



0 300 92



0 300 93



 
0 328 00



Conform to standard IEC 61084-2-2 and EN 50085-2-2
 For creating a link between trunking, column, mini-column, floor units or protecting cables on passageways
 Supplied with cover

Over floor trunking 50 x 12 mm


Pack	Cat.Nos	PVC trunking
54 ¹	0 300 92	Length 2 m, supplied with cover 3 compartments Capacity 1: max. Ø9 mm Capacity 2: max. Ø6 mm Grey RAL 7030



Pack	Cat.Nos	Accessories
10	0 300 12	Cover joint
10	0 300 11	Flat angle


Over floor trunking 75 x 18 mm

Pack	Cat.Nos	PVC trunking
36 ¹	0 300 88	Length 2 m, supplied with cover 3 compartments Capacity 1: max. Ø14 mm Capacity 2: max. Ø11 mm
36 ¹	0 300 90	
36 ¹	0 300 93	

 


Pack	Cat.Nos	Accessories for PVC floor trunking
10	0 300 19	Cover joint
5	0 300 18	Flat angle

Pack	Cat.Nos	Aluminium trunking
20 ¹	0 300 91	Length 2 m, supplied with cover 3 compartments Capacity 1: max. Ø14 mm Capacity 2: max. Ø11 mm

 

Over floor trunking 92 x 20 mm

Pack	Cat.Nos	PVC trunking
18 ¹	0 328 00	Length 2 m, supplied with cover 4 compartments Equipped with 2 adhesive strips for better floor fixing Capacity 1: max. Ø14.5 mm Capacity 2: max. Ø9.5 mm RAL 7016

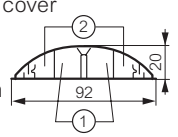

Pack	Cat.Nos	Accessories
10	0 328 07	End cap
10	0 328 03	Cover joint
5	0 328 02	Flat angle
1	0 328 05	Junction to floor duct

Junction between floor duct and trunkings

5	0 107 71 + 0 106 90	To be used with Cat.No 0 328 00
5	0 107 72 + 0 106 90	For cover 65 mm For cover 85 mm

1: Number of metres in pack