

## Floor sockets




0 897 02 (equipped)

Pack	Cat.Nos	Receptacles for floor sockets
		<p>Extra slim plate IP 44 - IK 08            Equipped with a 180° opening flap            Extra flat finish: thickness 2 mm            Lighting base of receptacle by white LED            To be equipped with 2 modules square version            Arteor or Mosaic functions:</p> <ul style="list-style-type: none"> <li>- socket outlets without cover, German, Euro-US, Swiss, Danish, Israeli and French standards</li> <li>- Double USB chargers</li> <li>- RJ 11 and RJ 12 sockets</li> <li>- Television sockets</li> <li>- RJ 45 sockets UTP, FTP and STP without controlled access</li> <li>- loudspeaker sockets</li> <li>- HDMI sockets</li> <li>- HD 15 sockets without jack</li> </ul>
1	0 897 00	<b>Square receptacle</b>
1	0 897 10	<ul style="list-style-type: none"> <li>● Stainless steel</li> <li>● Golden brushed</li> </ul>
1	0 897 01	<b>Round receptacle</b>
1	0 897 11	<ul style="list-style-type: none"> <li>● Stainless steel</li> <li>● Golden brushed</li> </ul>
1	0 897 02	<b>Rectangular receptacle</b>
1	0 897 12	<ul style="list-style-type: none"> <li>● Stainless steel</li> <li>● Golden brushed</li> </ul>
		<b>Boxes and accessories</b>
6	0 819 88	<p>Floor box            Flush-mounting box for concrete slab (50 to 80 mm thick) or raised access floor (10 to 40 mm thick) using saw Cat.No 0 800 88 Ø80 mm            Can be joined to make multi-gang assemblies</p>
1	0 885 08	<p>Hole saw            Ø80 mm</p>
10	0 897 19	<p>Indicator light with white LED for floor socket            Used to backlight the outline of the socket for easier location</p>
10	0 801 88	<p>Box for wall or furniture            Multimaterial simple Batibox flush-mounting box Ø80 mm            Used to install the floor socket in any type of partition or on furniture (such as a work surface)            Depth 50 mm</p>
1	0 897 09	<p>Kit consisting of 10 long screws and 30 blanking plates for positioning on the socket outlets            Used to equip 5 sockets            For use where there are thick coverings (such as carpets) in order to fix the plate to the box            Cat.No 0 819 88 or 0 801 88</p>


## Floor sockets

### Installation in concrete or technical floor

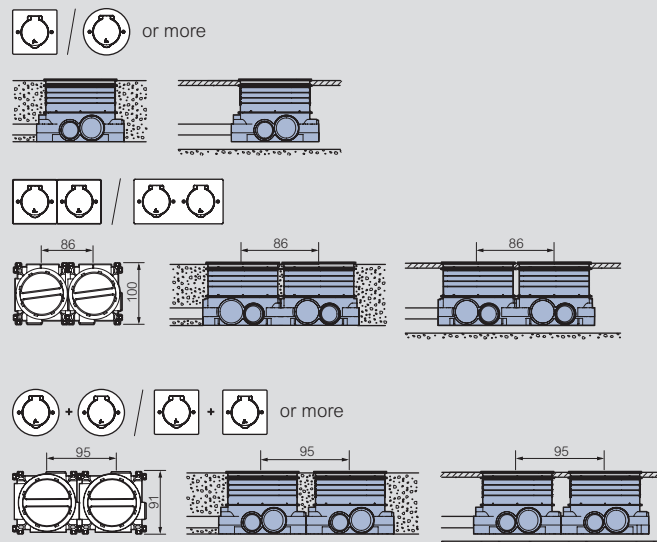


### Dimensions

#### Single sockets

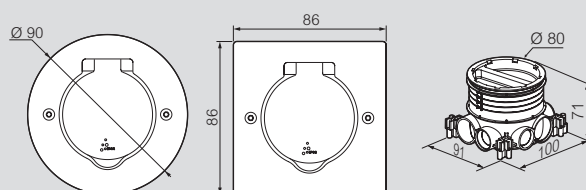

#### Double sockets

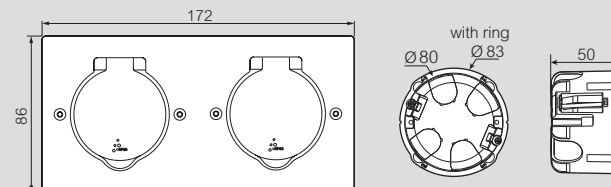

### Technical characteristics

#### Protection index

IP 44/ IK 08 : closed flap  
 Cover open at 180°

#### Material

Stainless steel / Golden brushed  
 Zamak  
 Fixing screw : Torx type T10 stainless steel