


# Mosaic™ surface-mounting boxes and adaptors

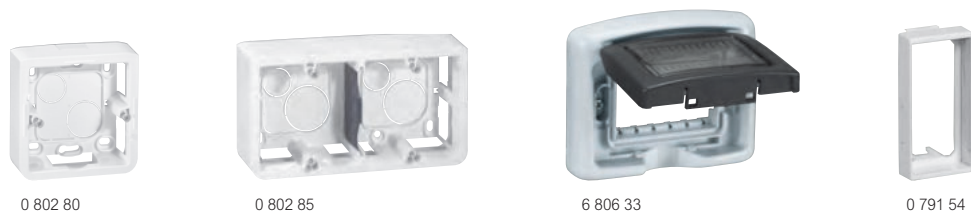

Selection chart for boxes, supports and plates p. 1198-1199

Pack	Cat.Nos	Surface-mounting boxes	Pack	Cat.Nos	Plexo 55 modular support frames IP 55 - IK 07
5	0 802 80	<b>For 2 modules (support Cat.No 0 802 51)</b> Equipped with a 20 x 12.5 mm removable entry	10	0 695 80L	<b>For 2-module Mosaic mechanisms</b> Can be equipped with any Mosaic function in order to obtain an IP 55 wiring accessory
5	0 802 81	Depth 30 mm			Adaptor with smoked polycarbonate flap
		Depth 40 mm	1	0 695 79L	Adaptor with smoked polycarbonate flap lockable with special tool below (not supplied)
2	0 802 89	<b>For 3 modules (support Cat.No 0 802 59)</b> Equipped with a 20 x 12.5 mm removable entry	1	0 919 45	Security tool For changing vandal-proof screws
		Depth 40 mm			<b>For 3-module Mosaic mechanisms</b>
5	0 802 85	<b>For 4, 5 or 2 x 2 horizontal modules (support Cat.No 0 802 52)</b> Equipped with a 32 x 12.5 mm removable entry	1	6 806 32	Weatherproof IP 55 plate frames with membrane
		Depth 40 mm	1	6 806 33	Allow operations of switches without opening cover maintaining IP 55 rating
5	0 802 86	<b>For 6, 8 or 3 x 2 horizontal modules (support Cat.No 0 802 53)</b> Equipped with a 32 x 12.5 mm removable entry			White
		Depth 40 mm			Grey
5	0 802 84	<b>For 10 or 4 x 2 horizontal modules (support Cat.No 0 802 54)</b> Equipped with a 40 x 20 mm removable entry			<b>Adaptors for mounting on Mosaic 50 mm supports</b>
		Depth 40 mm			<b>For replacing Mosaic mechanisms (50 x 50 mm) without having to change the plate or the support frame</b>
5	0 802 82	<b>For 5 or 2 x 2 vertical modules (support Cat.No 0 802 52)</b> Equipped with a 20 x 12.5 mm removable entry	10	0 791 54	Adaptor for 1-module mechanism (width 22.5 x 45 mm)
		Depth 40 mm	10	0 791 53	Adaptor for 2-module mechanisms (width 45 x 45 mm)
5	0 802 83	<b>For 3 x 2 vertical modules (support Cat.No 0 802 53)</b> Equipped with a 20 x 12.5 mm removable entry			
		Depth 40 mm			
1	0 802 74	<b>For 2 x 5 or 2 x 2 x 2 modules (support Cat.No 0 802 64)</b> Equipped with two 40 x 20 mm removable entries			
		Depth 46 mm			
1	0 802 76	<b>For 2 x 6, 2 x 8 or 2 x 3 x 2 modules (support Cat.No 0 802 66)</b> Equipped with three 40 x 20 mm removable entries			
		Depth 46 mm			
1	0 802 78	<b>For 2 x 10 modules (support Cat.No 0 802 68)</b> Equipped with four 40 x 20 mm removable entries			
		Depth 46 mm			

Mosaic™ plates,  
p. 1202

