


# steel perimeter trunking system – 170 x 63 mm

for dado or skirting applications (continued)

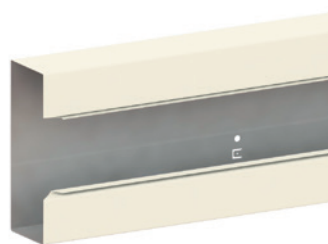

MP351236



MP351526



MP351306



MP351046




MP351106








MP351076

Selection charts **p. 4-5**  
Dimensions and technical information **p. 16-19**  
Installation material **p. 19**

 Pack	Cat. Nos.	Fittings (continued)
1	MP351046	<b>End cap</b> <sup>(11)</sup>
10	MP351106	<b>Cover strap</b> <sup>(12)</sup> Width – 25 mm
8	MP351076	<b>Tolerance cover strap</b> <sup>(13)</sup> Width – 40 mm
1	MP351486	<b>Wall flange plate</b> <sup>(14)</sup>
1	MP351516	<b>Wall flange closing plate</b> <sup>(15)</sup>
1	MP351456	<b>Support flange</b>
1	MP351409	<b>Riser trunking body 170 x 38 mm</b> <sup>(16)</sup> Pre-galvanised Length – 2 m
1	MP351439	<b>Riser trunking lid</b> <sup>(17)</sup> Friction fit Length – 1 m
1	MP351499	<b>Earthing wire</b> Length – 300 mm



Pack	Cat. Nos.	Regular power and data separation
20	MP351319	<b>Universal snapper clip</b> <sup>(18)</sup> Multifunction clip for fitting of divider, separation of cables (50 mm) and additional support of lid
10	MP351189	<b>Divider</b> <sup>(20)</sup> Requires universal snapper clip Cat. No. MP351319 Length – 1 m
10	MP351289	<b>Additional partition for the base</b> <b>Base divider</b> <sup>(1)</sup> Fixing bracket required (below) Length – 2 m Height – 45 mm, for type 170/170A
10	MP351309	<b>Base divider fixing bracket</b> <sup>(1)</sup> Height – 44 mm, for type 170 1 per metre required
1	MP351469	<b>Additional products IP 40 / IK 07</b> <b>Internal lid support</b> <sup>(1)</sup> Fits inside lid joints to achieve IP 40
1	MP351250	<b>Internal bend lid</b> To achieve IP 40 on internal bends
5	MP351449	<b>End support bracket</b> <sup>(1)</sup> Provides additional lid support at end of run Use to achieve IK 07
5	MP351459	<b>Tee support bracket</b> <sup>(1)</sup> Fits inside lid joints to achieve IP 40 at tee junction
1	MP351399	<b>Accessories</b> <b>Acoustic insulation block</b> <sup>(19)</sup> For use when trunking passes through walls to reduce noise travel Self extinguishing plastic Acoustic tested according to NEN 5077/ISO 140/4
1	MP351536	<b>Cutting support block</b> Holds trunking in position and guides saw for a straight cut Steel
1	MP351029	<b>Touch-up paint</b> Contents – 10 ml

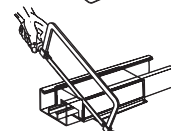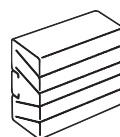   

1: Internal components supplied unpainted